


Data sheet | Item number: 2004-433

Push-in type jumper bar; insulated; from 1 to 3; Nominal current 32 A

www.wago.com/2004-433

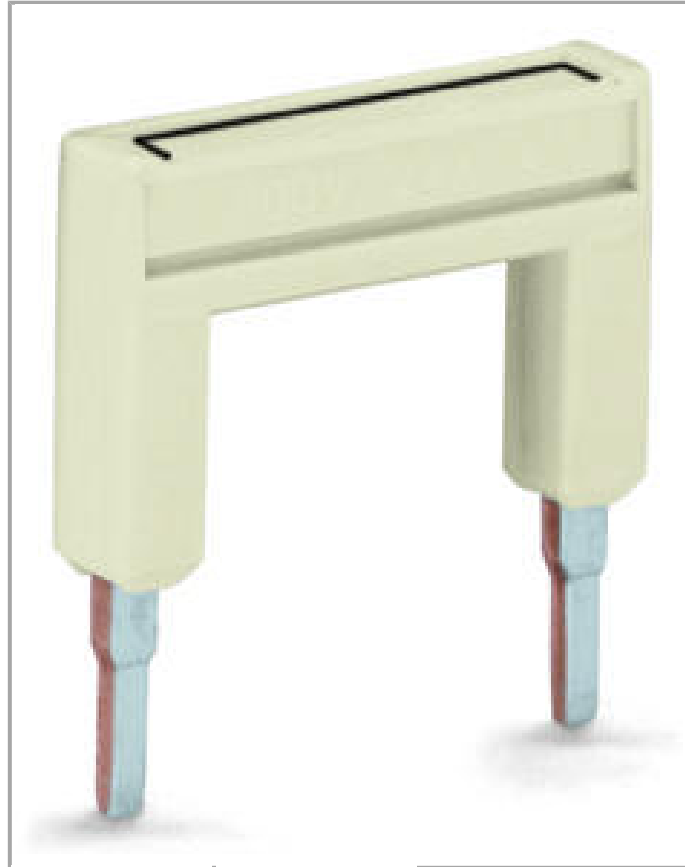

RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color:

Data

Electrical data

Rated current (Ex e II)	30 A
-------------------------	------

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	800 V
-------------------------	-------

Rated current	32 A
---------------	------

Geometrical Data

Width	16.5 mm / 0.65 inch
-------	---------------------



Height	19 mm / 0.748 inch
Depth	4.1 mm / 0.161 inch

Material Data

Color	light gray
Fire load	0.01 MJ
Weight	1.761 g

Commercial data

Country of origin	DE
GTIN	4044918583077
Customs Tariff No.	85366990990
Product Group	22 (TOPJOB S)

Downloads**Documentation****Bid Text**

2004-433	Oct 26, 2017	DOC 24.1 kB	Download
----------	--------------	----------------	----------

smartDATA**CAD data**

3D Download 2004-433	URL	Download
----------------------	-----	----------

Product family**TOPJOB® S**

TOPJOB® S: In various industrial applications and modern building installations, WAGO's wide and versatile range of rail-mount terminal blocks provides more than just reliable electrical connections.

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.