


## Data sheet | Item number: 770-626

T-distribution connector; 4-pole; Cod. A; 1 input; 2 outputs; 2 locking levers

[www.wago.com/770-626](http://www.wago.com/770-626)

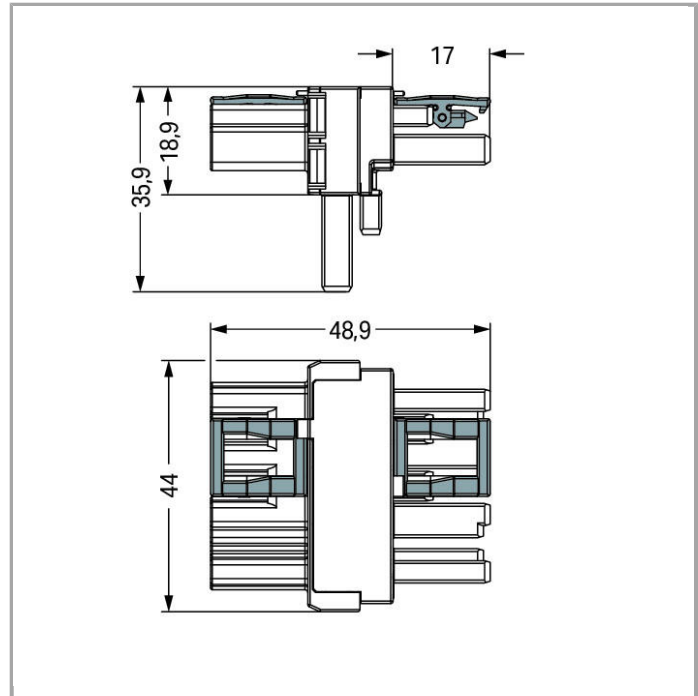

### Item description

#### Note:

All connectors for mounted installations (snap-in versions for lighting fixtures or devices, all types of PCB and distribution connectors) are factory-equipped with locking levers to ensure plugs and sockets are securely locked. Additional locking levers are only required for flying leads (plug /socket).

### Data

#### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	400 V
Rated impulse voltage (III / 3)	6 kV
Rated current	25 A
Legend (ratings)	(III / 3) ≙ Overvoltage category III / Pollution degree 3



### Connection data

No. of poles	4
Total number of potentials	4
Ground function	with preceding GND contact

### Geometrical Data

Pin spacing	10 mm (0.394 inch)
Width	44 mm / 1.732 inch
Height	36.1 mm / 1.421 inch
Depth	48.9 mm / 1.925 inch

### Mechanical data

Coding	A
Mating force of a plug-in connection	approx. 20 ... 70 N (depending on pole number)
Retention force of a plug-in connection	when locked: > 80N
Unmating force of a plug-in connection	when unlocked: approx. 20 ... 70 N (depending on pole number)
Type of distribution connector	T-distribution connector
Marking	N 2 L 1 L'
Degree of protection	IP20
Potential marking	N 2/L 1/L'

### Plug connection

Contact type (pluggable connector)	Socket/plug
Mismating protection	Yes
Locking of plug-in connection	locking lever
Locking lever	yes

### Material Data

Color	black
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Contact material	Copper or copper alloy, surface-treated
Fire load	0.419 MJ
Weight	21 g

### Environmental Requirements

Surrounding air (operating) temperature	-35 ... 85 °C
-----------------------------------------	---------------

## Commercial data




Country of origin	DE
GTIN	4044918935074
Customs Tariff No.	85366990990

## Approvals / Certificates

### Country specific Approvals

Logo	Approval	Certificate name
	<b>CCA</b> DEKRA Certification B.V.	2173495.02
	<b>CCA</b> DEKRA Certification B.V.	NL-32105

### Ship Approvals

Logo	Approval	Certificate name
	<b>ABS</b> American Bureau of Shipping	14-HG1241528-PDA
	<b>DNV GL</b> Det Norske Veritas, Germanischer Lloyd	TAE00001Z6
	<b>LR</b> Lloyds Register	02/20050 (E6)

### UL-Approvals

Logo	Approval	Certificate name
	<b>cURus</b> Underwriters Laboratories Inc.	E45171 Sec. 9

## Compatible products

### assembling

	Item no.: 770-354 Mounting carrier	<a href="http://www.wago.com/770-354">www.wago.com/770-354</a>
------------------------------------------------------------------------------------	---------------------------------------	----------------------------------------------------------------

### protection



**Item no.: 770-201**

Lockout cap; for socket; 12-pole; separable

[www.wago.com/770-201](http://www.wago.com/770-201)

**Item no.: 770-221**

Lockout cap; for socket; 12-pole; separable

[www.wago.com/770-221](http://www.wago.com/770-221)



**Item no.: 770-360**

Lockout cap; for plugs; 5-pole; separable

[www.wago.com/770-360](http://www.wago.com/770-360)

## Downloads

### Documentation

#### Bid Text

770-626	Feb 8, 2016	DOC	Download
WINSTA MIDI 4-polig		23.6 kB	

## smartDATA

### CAD data

3D Download 770-626	URL	Download
---------------------	-----	----------

Subject to changes.