
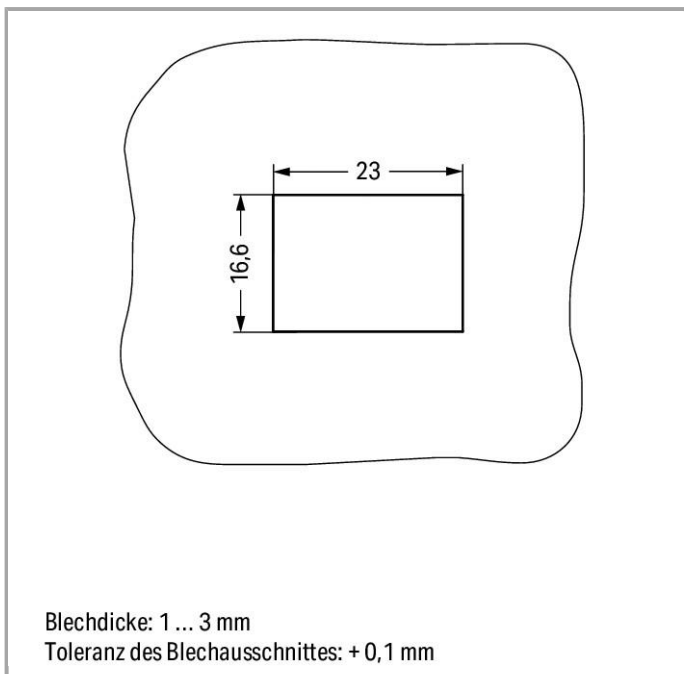


RoHS  Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color:

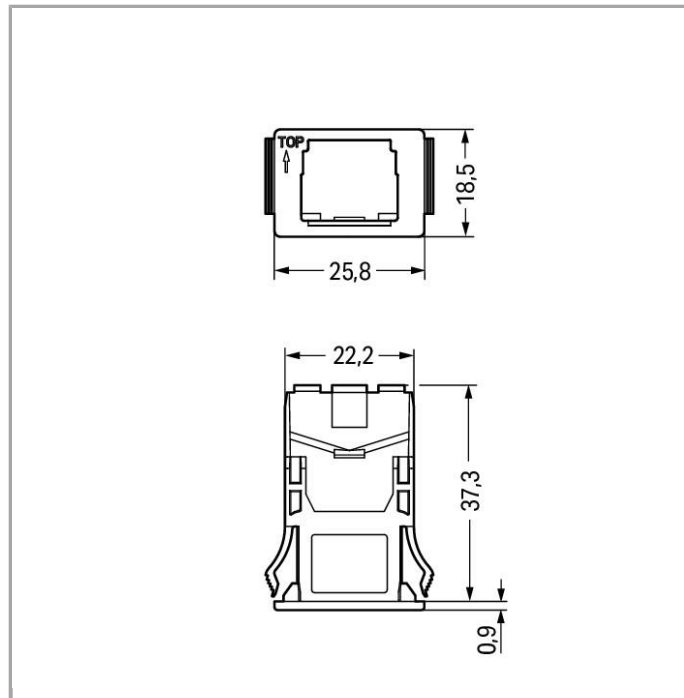

Blechdicke: 1 ... 3 mm  
Toleranz des Blechausschnittes: + 0,1 mm

Data

Electrical data

## Ratings per IEC/EN 60664-1

Legend (ratings)

(III / 3) ≙ Overvoltage category III / Pollution degree 3

## Geometrical Data

Width	25.8 mm / 1.016 inch
Height	18.5 mm / 0.728 inch
Depth	38.75 mm / 1.526 inch

## Mechanical data

Gehäuseblechstärke	1 ... 3 mm / 0.039 ... 0.118 inch
Mounting type	Snap-in
Degree of protection	IP20

## Material Data

Color	white
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load	0.081 MJ
Weight	2.71 g

## Environmental Requirements


Surrounding air (operating) temperature	-35 ... 85 °C
---	---------------

## Commercial data




Country of origin	DE
GTIN	4050821261179
Customs Tariff No.	39269097900
Product Group	20 (WINSTA)

## Approvals / Certificates

### Country specific Approvals

Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	2173495.02
	CCA DEKRA Certification B.V.	NL-32105

### Ship Approvals

Logo	Approval	Certificate name
	<b>ABS</b> American Bureau of Shipping	14-HG1241528-PDA
	<b>DNV GL</b> Det Norske Veritas, Germanischer Lloyd	TAE00001Z6
	<b>LR</b> Lloyds Register	02/20050 (E6)

## Compatible products

### Locking lever

	<b>Item no.: 770-140</b> Locking lever; for sockets; for manual operation	<a href="http://www.wago.com/770-140">www.wago.com/770-140</a>
--	--	--

## Downloads

### Documentation

#### Bid Text

770-337 WINSTA MIDI 2-polig	Jan 19, 2016	DOC 23.6 kB	Download
--------------------------------	--------------	----------------	----------

## smartDATA

### CAD data

3D Download 770-337	URL	Download
---------------------	-----	----------

Subject to changes.