
 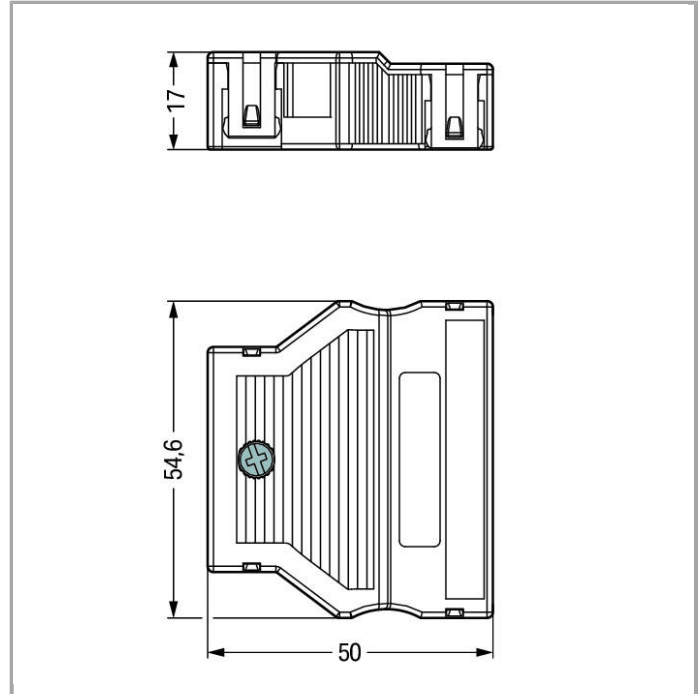


Data sheet | Item number: 770-505/023-000

Strain relief housing; 5-pole; for 2 cables; 5.0 ... 9.0 mm; 55 mm

www.wago.com/770-505/023-000



Data

Connection data

No. of poles	5
Connectable sheathed cable diameter	5 ... 9 mm
Strip length	55 mm

Geometrical Data

Width	54.6 mm / 2.15 inch
Depth	50 mm / 1.969 inch

Mechanical data

Degree of protection	IP20
----------------------	------

Material Data

Color	black
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load	0.38 MJ

Weight	13.74 g
--------	---------

Environmental Requirements


Surrounding air (operating) temperature	-35 ... 85 °C
---	---------------

Commercial data



Country of origin	DE
GTIN	4044918065580
Customs Tariff No.	85389099990
Product Group	20 (WINSTA)

Approvals / Certificates

Country specific Approvals

Logo	Approval	Certificate name
	VDE VDE Prüf- und Zertifizierungsinstitut	40029808

Ship Approvals


Logo	Approval	Certificate name
	DNV GL Det Norske Veritas, Germanischer Lloyd	TAE00001Z6
	LR Lloyds Register	02/20050 (E6)

UL-Approvals

Logo	Approval	Certificate name
	cURus Underwriters Laboratories Inc.	E45171 Sec. 9

Compatible products

Marking accessories

	Item no.: 210-333 Marking strips; as a DIN A4 sheet; Strip width 6 mm; Strip length 182 mm; plain; Self-adhesive	www.wago.com/210-333
--	---	--



Downloads

Documentation

Bid Text

770-505/023-000	Jan 21, 2016	DOC	Download
WINSTA MIDI 5-polig		24.1 kB	

smartDATA

CAD data

3D Download 770-505/023-000	URL	Download
-----------------------------	-----	----------

Subject to changes.