


## Data sheet | Item number: 770-512/041-000

Strain relief housing; 2-pole; with locking clip; for 1 cable; 7.0 ... 10.5 mm; 35 mm



[www.wago.com/770-512/041-000](http://www.wago.com/770-512/041-000)

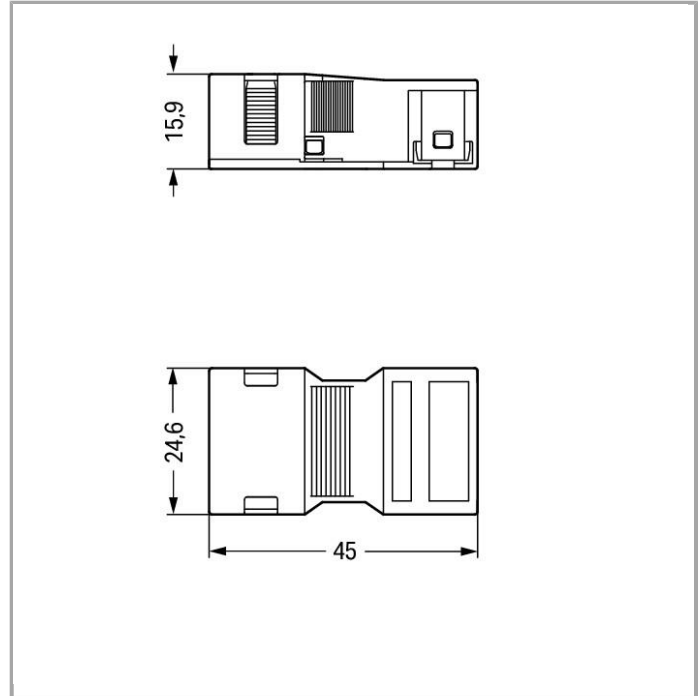

### Data

#### Connection data

No. of poles	2
Connectable sheathed cable diameter	7 ... 10.5 mm
Strip length	35 mm

#### Geometrical Data

Width	24.6 mm / 0.969 inch
Height	15.9 mm / 0.626 inch
Depth	45 mm / 1.772 inch

#### Mechanical data

Degree of protection	IP20
----------------------	------

#### Material Data

Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load	0.192 MJ

Weight	6.65 g
--------	--------

### Environmental Requirements


Surrounding air (operating) temperature	-35 ... 85 °C
---	---------------

### Commercial data

Country of origin	DE
GTIN	4050821137573
Customs Tariff No.	85389099990


### Approvals / Certificates

#### Ship Approvals

Logo	Approval	Certificate name
	LR Lloyds Register	02/20050 (E6)

### Compatible products

#### Marking accessories

	Item no.: 210-333 Marking strips; as a DIN A4 sheet; Strip width 6 mm; Strip length 182 mm; plain; Self-adhesive	<a href="http://www.wago.com/210-333">www.wago.com/210-333</a>
--	---	--

### Downloads

#### Documentation

#### Bid Text

770-512/041-000 WINSTA MIDI 2-polig	Jan 19, 2016	DOC 24.1 kB	Download
--	--------------	----------------	----------

### smartDATA

#### CAD data

3D Download 770-512/041-000	URL	Download
-----------------------------	-----	----------



Subject to changes.

---

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.