

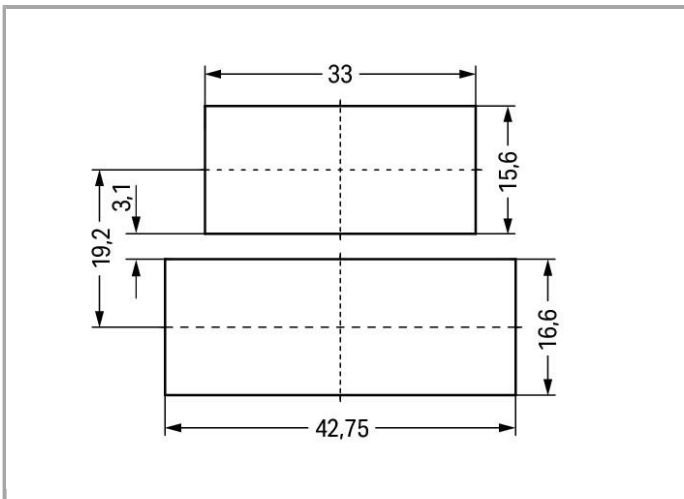


Data sheet | Item number: 770-507/047-000

Strain relief housing; 7-pole; with locking clip; for 1 cable; 8.0 ... 15.0 mm; 55 mm

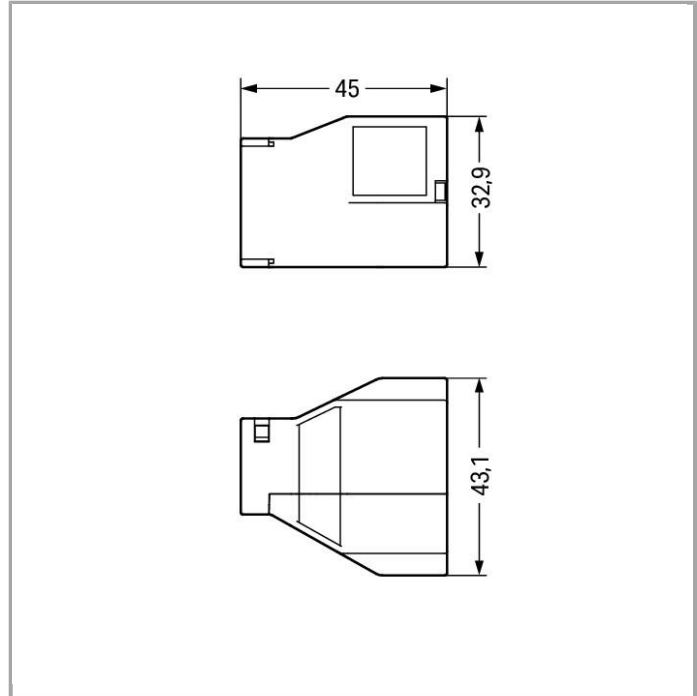

www.wago.com/770-507/047-000

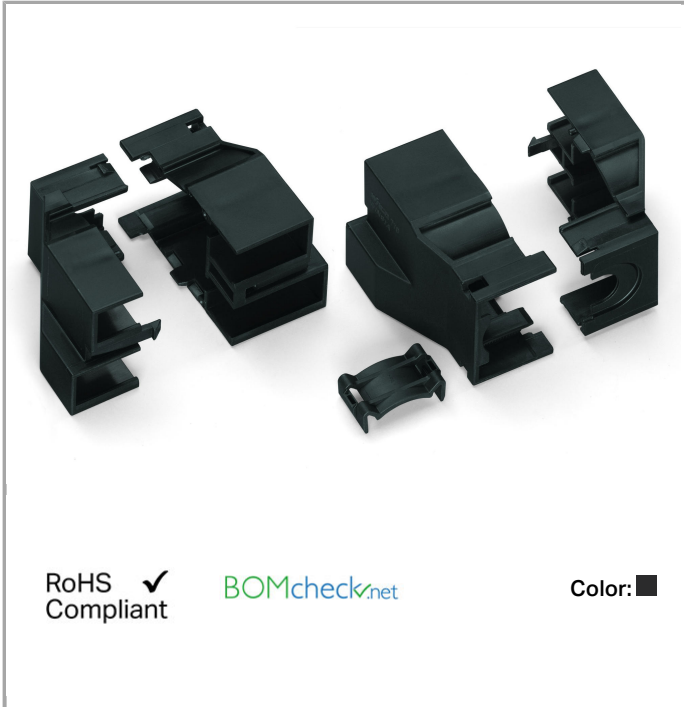

Data

Connection data

No. of poles	7
Connectable sheathed cable diameter	8 ... 15 mm
Strip length	55 mm

Geometrical Data

Width	43.1 mm / 1.697 inch
Height	32.9 mm / 1.295 inch
Depth	45 mm / 1.772 inch

Mechanical data

Degree of protection	IP20
----------------------	------

Material Data

Color	black
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load	0.669 MJ
Weight	22.32 g

Environmental Requirements

Surrounding air (operating) temperature	-35 ... 85 °C
---	---------------

Commercial data

Country of origin	DE
GTIN	4045454554453
Customs Tariff No.	39269097900

Approvals / Certificates

Ship Approvals

Logo	Approval	Certificate name
	LR Lloyds Register	02/20050 (E6)

Compatible products

Marking accessories



Item no.: 210-333

Marking strips; as a DIN A4 sheet; Strip width 6 mm; Strip length 182 mm; plain; Self-adhesive

www.wago.com/210-333



Downloads

Documentation

Bid Text

770-507/047-000	Jan 20, 2016	DOC	Download
WINSTA MIDI 7-polig		24.1 kB	

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
Hansastr. 27
32423 Minden
Phone: +49571 887-0 | Fax: +49571 887-169
Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
We are always happy to take your call at +49 (571) 887-44222.