


DIGITUS USB 2.0 connection cable

AK-300110-010-S
EAN

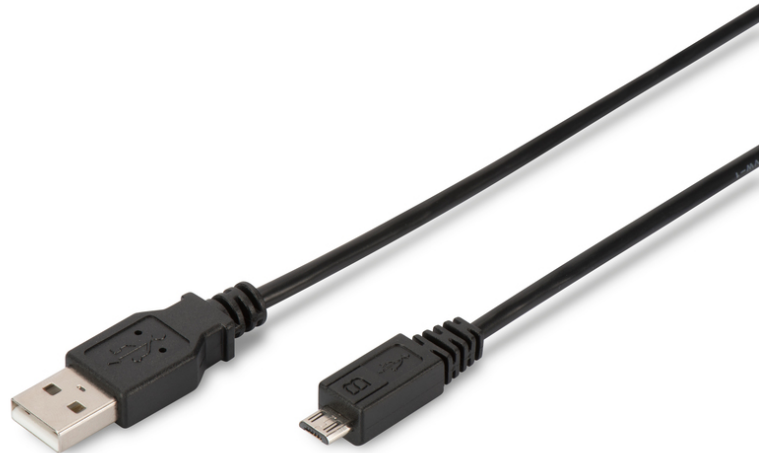

USB 2.0 connection cable, type A - micro B M/M, 1.0m, USB 2.0 conform, b1

For connection of external USB devices (with USB micro B socket, e.g. MP3 -player, smart phone or external HDD enclosure) to the USB host (e. g. PC, notebook or USB hub). Data transfer rate up to 480 Mbps (High-Speed).

Allows a reliable and fast connection of external USB devices with the PC.

- Data transfer rate up to 480MB/s
- Power supply up to 5V/0,5A and 2.5W
- Copper wire, foil and braid shielding for robustness and reliable connection
- AWG: 28

- Connector surface: nickel-plated
- Color cable: black
- Color connector: black
- Hoods: molded
- Shielding: Double shielding
- Ferrite filter: none
- Assortment: USB Cables
- USB-C Products: no
- Length: 1 m
- Packaging: Polybag
- Connector 1: USB A, plug
- Connector 2: Micro USB B, plug
- USB compliance: USB 2.0
- Wire material: CU

Logistics						
	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm ³
Packaging Unit Carton	300	12.00	40.00	38.00	23.00	34,960.00
Packaging Unit Inside	10	0.40	24.00	21.00	3.00	1,512.00
Packaging Unit Single	1	0.04	19.00	16.00	1.50	456.00
Net single without Packaging	1	0.03	19.00	16.00	1.50	456.00

More images:



