

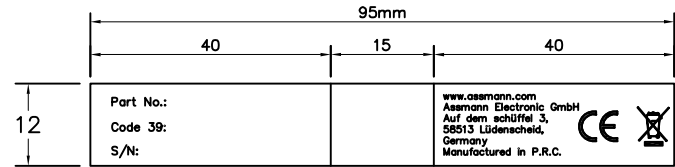
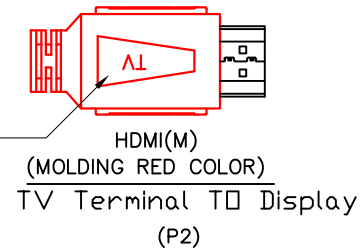
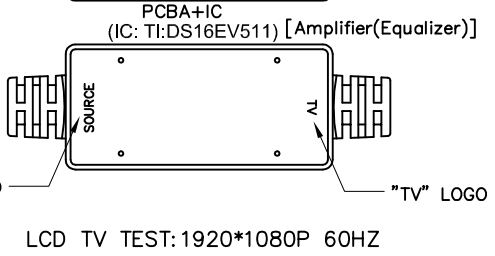
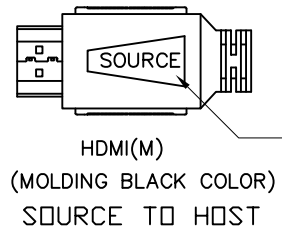


REACH&RoHS Compliant

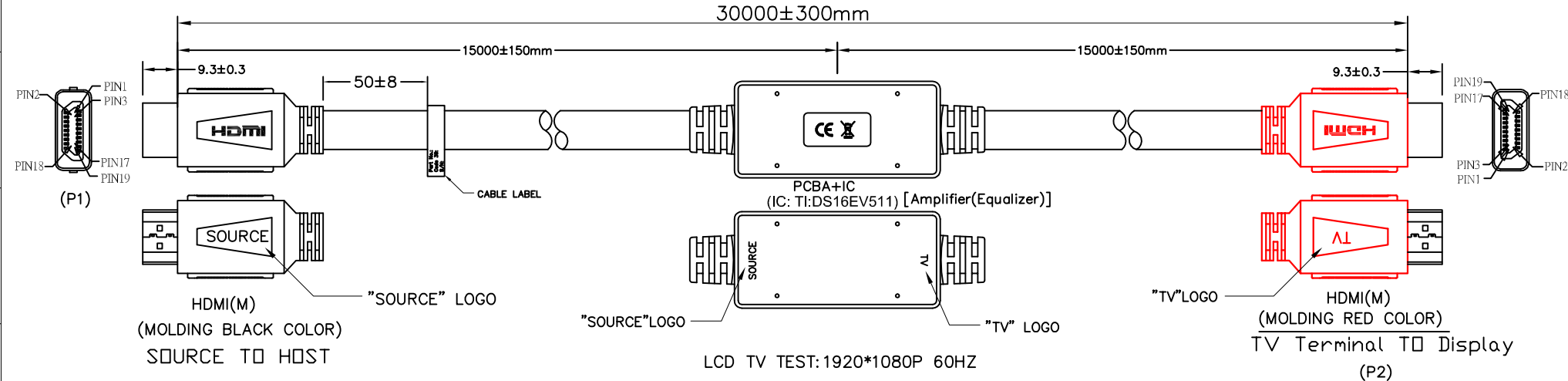

CABLE LABEL 1
(Color of paper: white/text: black)

 
Part No.: 客人料号
Code 39: 随订单出货批次更改
S/N: WWYY
Year(2017=17)
Week

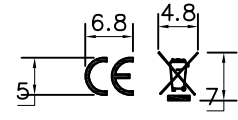


NOTE: CABLE MUST Print: E314459 兄 AWM 20276 80°C 30V VW-1 HIGH SPEED HDMI CABLE WITH ETHERNET Assmann Electronic GmbH, 58513 Lüdenscheid, Germany

NOTE:
Operating Temperature : <80°
Operating Humidity: <75%
Storage Temperature: <50°
Storage Humidity <65%

- CABLE: 26AWG(1/0.404BC),UL20276,AL/MY+B-FOIL,(#26*1P+D+AL)*5PCS+26AWG*4C, OD=8.6±0.2mm,BLACK COLOR,PVC JACKET.
- LENGTH: 30M.
- CONNECTORS: P1&P2: HDMI(M)*2PCS(BLACK INSULATOR)(SHELL GOLD PLATED).
- MOLD: MOLDING TYPE.
- CONTACTS:



- Test machine test condition.
 - A.100% OPEN,SHORT&INTERMITANCE TEST.
 - B.CONDUCTOR RESISTANCE: 3ohms MAX:
 - C.INSULATION RESISTANCE: 5M Min/,10ms:
- ALL MUST BE MEET ON ROHS COMPLIANT.

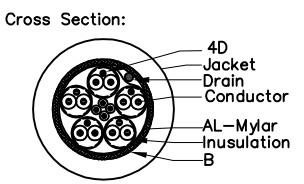

	Date	Name	Part No.
Drawn by	2020.05.19	Yuwenming	AK-330105-300-S
Checked by	2020.05.19	Zhouwei	EAN:
Approved by			Title
ASSMANN Electronic GmbH			HDMI M/M
			Scale Unit
80496			Sheet 1/2