
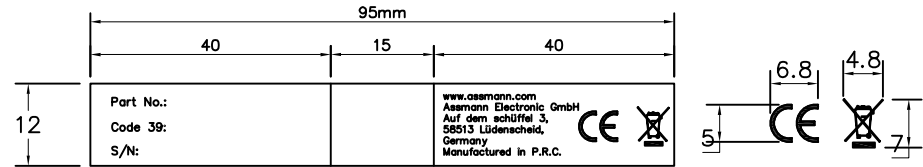


REACH&RoHS Compliant

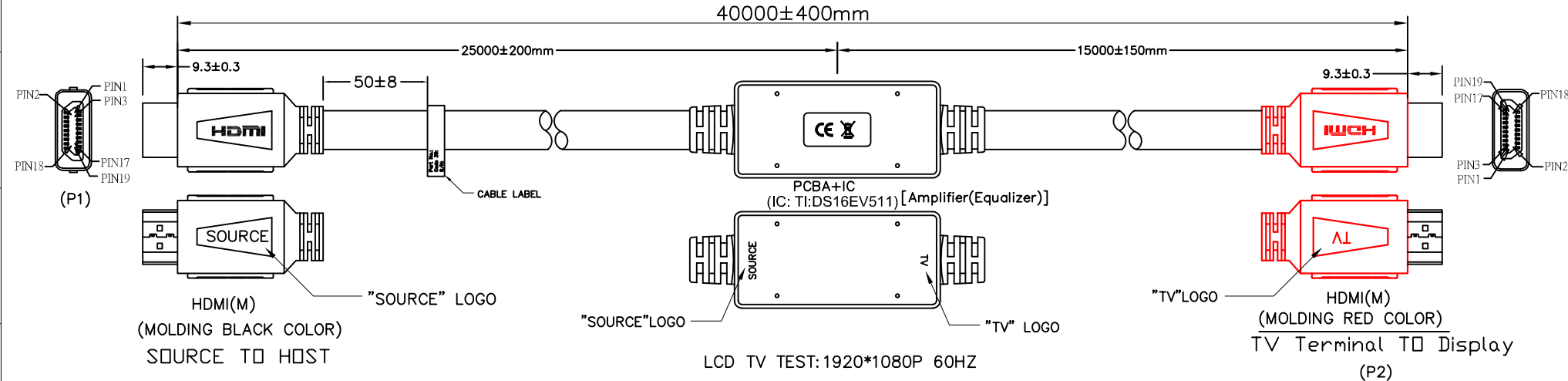

CABLE LABEL 1
 (Color of paper: white/text: black)
 Part No.: 客人料号
 Code 39: 随订单出货批次更改
 S/N: WWYY
 Year(2017=17)
 Week


NOTE: CABLE MUST Print: E314459 兄 AWM 20276 80°C 30V VW-1 HIGH SPEED HDMI CABLE WITH ETHERNET Assmann Electronic GmbH, 58513 Lüdenscheid, Germany

NOTE:
 Operating Temperature : <80°
 Operating Humidity: <75%
 Storage Temperature: <50°
 Storage Humidity <65%

- CABLE: 24AWG(1/0.515BC),UL20276,AL/MY+B-FOIL,(#24*1P+D+AL)*5PCS+24AWG*4C, OD=9.5±0.2mm,BLACK COLOR,PVC JACKET.
- LENGTH: 40M.
- CONNECTORS: P1&P2: HDMI(M)*2PCS(BLACK INSULATOR)(SHELL GOLD PLATED).
- MOLD: MOLDING TYPE.
- CONTACTS:

HDMI(M)(P1)	1	3	2	4	6	5	7	9	8	10	12	11	14	19	17	13	15	16	18	64
HDMI(M)(P2)	1	3	2	4	6	5	7	9	8	10	12	11	14	19	17	13	15	16	18	64
	PAIR		G	PAIR		G	PAIR		G	PAIR		G	PAIR		G	4C				SHELL

- Test machine test condition.
 - A.100% OPEN,SHORT&INTERMITANCE TEST.
 - B.CONDUCTOR RESISTANCE: 3ohms MAX:
 - C.INSULATION RESISTANCE: 5M Min/,10ms:
- ALL MUST BE MEET ON ROHS COMPLIANT.

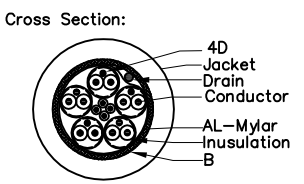

	Date	Name	Part No.
Drawn by	2020.05.19	Yuwenming	AK-330105-400-S
Checked by	2020.05.19	Zhouwei	EAN:
Approved by			Title
ASSMANN Electronic GmbH			HDMI M/M
			Scale Unit
80496			Sheet 1/2