

1

2

3

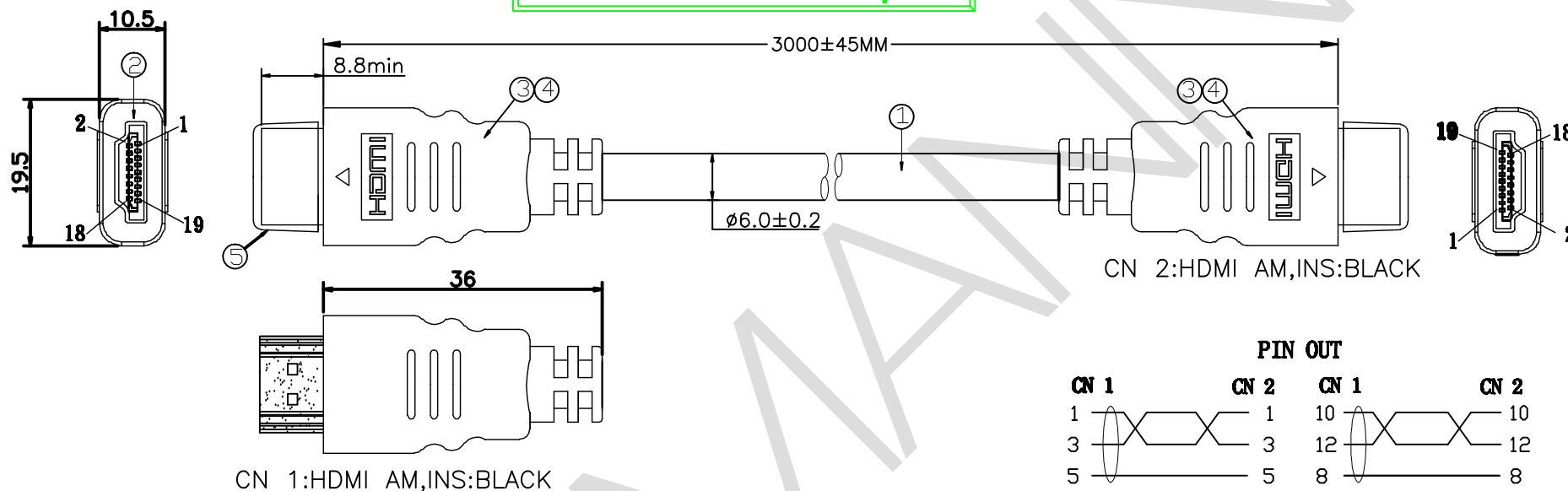
4

5

6

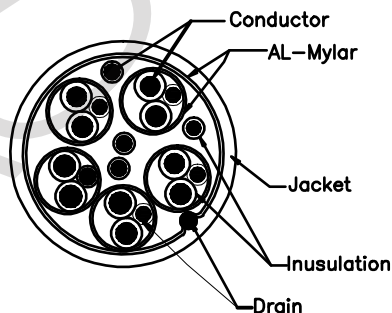
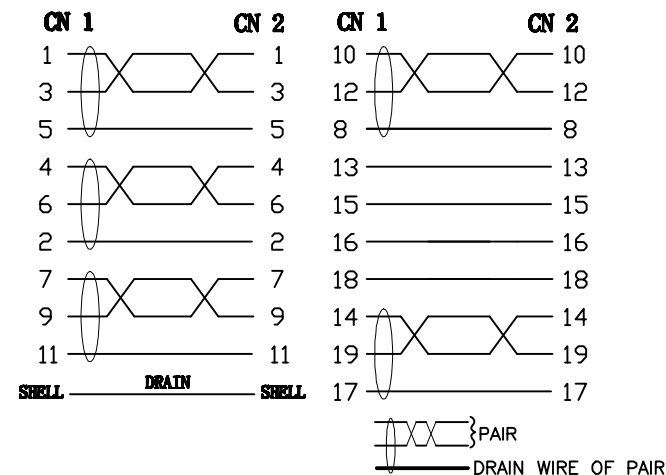
7

Signature	Revision History	Date	Rev.
Achy	For Bulk Production	JUL08,2016	00
Achy	Optimization of drawing	May,10,2017	01

RoHS & REACH Compliant**NOTES:**

- 1.Cable:(1/0.254BC*1P+1/0.254CCS+AL/M)*5C+1/0.254BC*4C+AL+1/0.254BC+B(64/0.12ALM), Jacket:PVC/Black,OD:6.0±0.2mm.Cable printing:High Speed HDMI Cable with Ethernet
- 2.Connector:CN1&CN2:HDMI A/M,Black Insulator,Shell:Gold plated>Contact:Gold plated
- 3.Inner moulded:LDPE.
- 4.Hood:Moulded type,PVC 88A,Color:Black.
- 5.Dust cap:For HDMI A type male,LDPE.
- 6.TEST:(1)100% OPEN SHORT & MISS WIRE TEST.
(2)CONDUCTOR RESISTANCE 3 ohm Max.
(3)INSULATION RESISTANCE:DC 300V 10MΩ Min
(4)HD-TV:1080P,60HZ.

Cross Section:

**PIN OUT**

Date	Name	Part No.
Drawn by May.10,2017	Achy	AK-330107-030-S
Checked by May.10,2017	Helen	EAN:4016032290964
Approved by 15May, 2017	Joe	
ASSMANN Electronic GmbH		Title HDMI High Speed connection cable,type A M/M,3.0m,w/Ethernrt,Ultra HD 60p, bl,gold
		Scale Unit
		N/A MM
		Sheet 1/2

	1	2	3	4	5	6	7																	
A	RoHS & REACH Compliant					<table border="1"> <tr> <th>Signature</th> <th>Revision History</th> <th>Date</th> <th>Rev.</th> </tr> <tr> <td>Achy</td> <td>For Bulk Productio</td> <td>JUL,08,2016</td> <td>00</td> </tr> <tr> <td>Achy</td> <td>Optimization of drawing</td> <td>May,10,2017</td> <td>01</td> </tr> </table>		Signature	Revision History	Date	Rev.	Achy	For Bulk Productio	JUL,08,2016	00	Achy	Optimization of drawing	May,10,2017	01	A				
Signature	Revision History	Date	Rev.																					
Achy	For Bulk Productio	JUL,08,2016	00																					
Achy	Optimization of drawing	May,10,2017	01																					
B	Package Details Single Cable <table border="1"> <thead> <tr> <th>P/N</th> <th>Cable Length</th> <th>Rolling Size (Single Cable)</th> <th>Polybag Type (Single Cable)</th> <th>Bag Size (Single Cable)</th> <th>Article Weight (Single Cable)</th> </tr> </thead> <tbody> <tr> <td>AK-330107-030-S</td> <td>3.0m</td> <td>130±10mm</td> <td>Ordinary Polybag (Heat Sealed)</td> <td>230*180*0.05mm</td> <td>0.122kg</td> </tr> </tbody> </table>					P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)	AK-330107-030-S	3.0m	130±10mm	Ordinary Polybag (Heat Sealed)	230*180*0.05mm	0.122kg	Single Cable		B				
P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)																			
AK-330107-030-S	3.0m	130±10mm	Ordinary Polybag (Heat Sealed)	230*180*0.05mm	0.122kg																			
C	Inner Packing Unit <table border="1"> <thead> <tr> <th>P/N</th> <th>Cable Length</th> <th>Quantity (Inner Packing Unit)</th> <th>Type (Inner Packing Unit)</th> <th>Size (Inner Packing Unit)</th> <th>Weight (Inner Packing Unit)</th> </tr> </thead> <tbody> <tr> <td>AK-330107-030-S</td> <td>3.0m</td> <td>10 pcs</td> <td>Polybag (Heat Sealed)</td> <td>490*330*0.04mm</td> <td>1.225kg</td> </tr> </tbody> </table>					P/N	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)	AK-330107-030-S	3.0m	10 pcs	Polybag (Heat Sealed)	490*330*0.04mm	1.225kg			C				
P/N	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)																			
AK-330107-030-S	3.0m	10 pcs	Polybag (Heat Sealed)	490*330*0.04mm	1.225kg																			
D	Carton Details <table border="1"> <thead> <tr> <th>P/N</th> <th>Cable Length</th> <th>Quantity (Carton)</th> <th>Measurement (Carton)</th> <th>N.W. (Carton)</th> <th>G.W. (Carton)</th> </tr> </thead> <tbody> <tr> <td>AK-330107-030-S</td> <td>3.0m</td> <td>50 pcs</td> <td>40x38x21cm</td> <td>6.2kg</td> <td>6.8kg</td> </tr> </tbody> </table>					P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)	AK-330107-030-S	3.0m	50 pcs	40x38x21cm	6.2kg	6.8kg	Inner Packing Unit		D				
P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)																			
AK-330107-030-S	3.0m	50 pcs	40x38x21cm	6.2kg	6.8kg																			
E	<table border="1"> <thead> <tr> <th>P/N</th> <th>Cable Length</th> <th>Quantity (Carton)</th> <th>Measurement (Carton)</th> <th>N.W. (Carton)</th> <th>G.W. (Carton)</th> </tr> </thead> <tbody> <tr> <td>AK-330107-030-S</td> <td>3.0m</td> <td>50 pcs</td> <td>40x38x21cm</td> <td>6.2kg</td> <td>6.8kg</td> </tr> </tbody> </table>					P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)	AK-330107-030-S	3.0m	50 pcs	40x38x21cm	6.2kg	6.8kg			E				
P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)																			
AK-330107-030-S	3.0m	50 pcs	40x38x21cm	6.2kg	6.8kg																			
F								F																
G						<table border="1"> <thead> <tr> <th></th> <th>Date</th> <th>Name</th> <th>Part No.</th> </tr> </thead> <tbody> <tr> <td>Drawn by</td> <td>May.10,2017</td> <td>Achy</td> <td>AK-330107-030-S</td> </tr> <tr> <td>Checked by</td> <td>May.10,2017</td> <td>Helen</td> <td>EAN:4016032290964</td> </tr> <tr> <td>Approved by</td> <td>15May, 2017</td> <td>Joe</td> <td></td> </tr> </tbody> </table>			Date	Name	Part No.	Drawn by	May.10,2017	Achy	AK-330107-030-S	Checked by	May.10,2017	Helen	EAN:4016032290964	Approved by	15May, 2017	Joe		G
	Date	Name	Part No.																					
Drawn by	May.10,2017	Achy	AK-330107-030-S																					
Checked by	May.10,2017	Helen	EAN:4016032290964																					
Approved by	15May, 2017	Joe																						
H	★ "ROTTERDAM" is for Sea Freight shipment ★ "COLOGNE" is for Air Freight shipment ★ "LUDENSCHIED" is for Fedex or UPS shipment					ASSMANN Electronic GmbH <table border="1"> <thead> <tr> <th>Title</th> <th>Scale Unit</th> <th>N/A MM</th> <th>Sheet 1/2</th> </tr> </thead> <tbody> <tr> <td>HDMI High Speed connection cable,type A M/M,3.0m,w/Ethernrt,Ultra HD 60p, bl,gold</td> <td></td> <td></td> <td></td> </tr> </tbody> </table>		Title	Scale Unit	N/A MM	Sheet 1/2	HDMI High Speed connection cable,type A M/M,3.0m,w/Ethernrt,Ultra HD 60p, bl,gold				H								
Title	Scale Unit	N/A MM	Sheet 1/2																					
HDMI High Speed connection cable,type A M/M,3.0m,w/Ethernrt,Ultra HD 60p, bl,gold																								
	1	2	3	4	5	6	7																	