


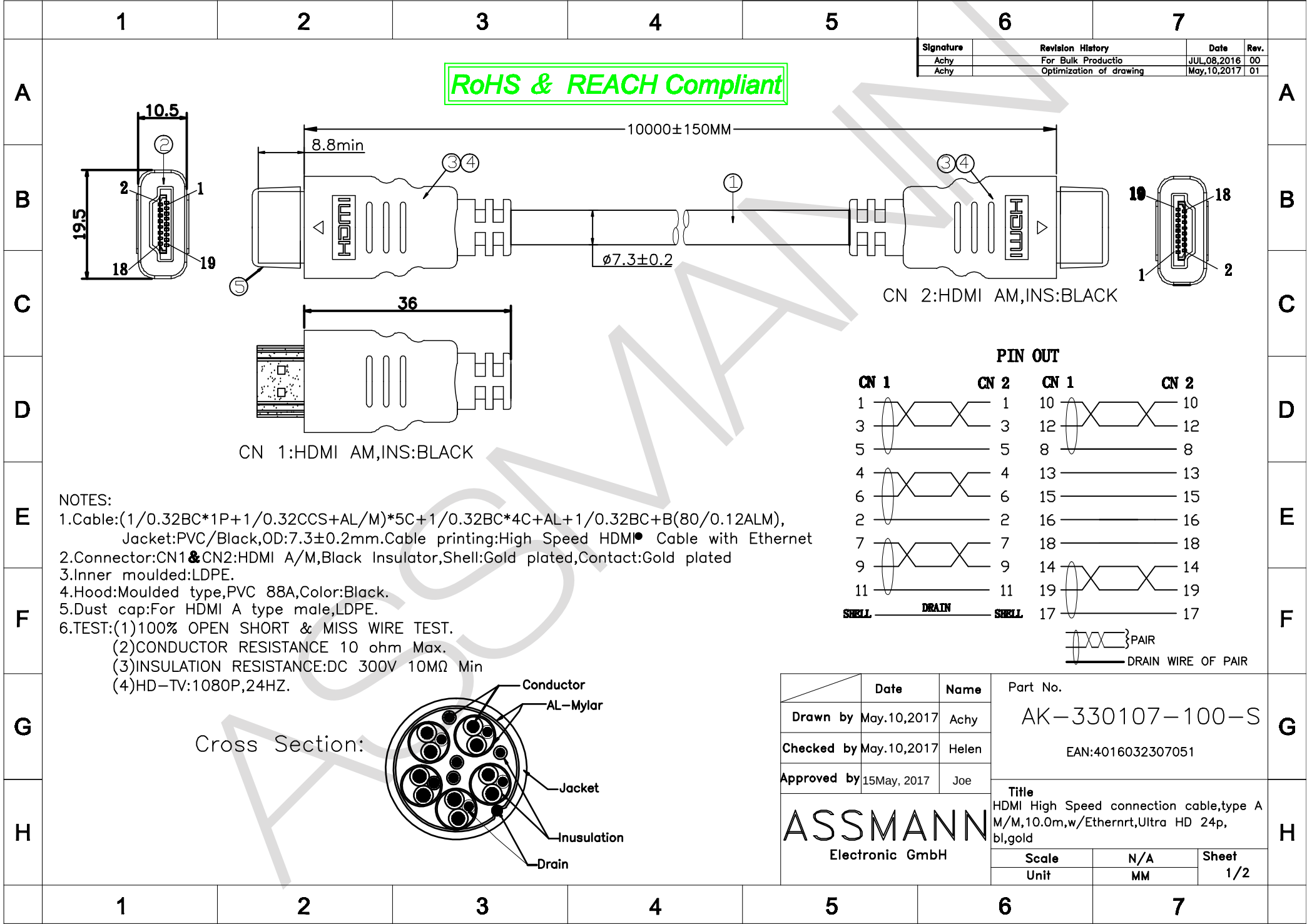

	1	2	3	4	5	6	7																	
A	RoHS & REACH Compliant					<table border="1" style="width:100%; border-collapse: collapse; font-size: 0.8em;"> <tr> <th style="width: 20%;">Signature</th> <th style="width: 40%;">Revision History</th> <th style="width: 20%;">Date</th> <th style="width: 20%;">Rev.</th> </tr> <tr> <td>Achy</td> <td>For Bulk Productio</td> <td>JUL,08,2016</td> <td>00</td> </tr> <tr> <td>Achy</td> <td>Optimization of drawing</td> <td>May,10,2017</td> <td>01</td> </tr> </table>		Signature	Revision History	Date	Rev.	Achy	For Bulk Productio	JUL,08,2016	00	Achy	Optimization of drawing	May,10,2017	01	A				
Signature						Revision History	Date	Rev.																
Achy	For Bulk Productio	JUL,08,2016	00																					
Achy	Optimization of drawing	May,10,2017	01																					
B	Package Details Single Cable <table border="1" style="width:100%; border-collapse: collapse; text-align: center;"> <tr> <th style="width: 15%;">P/N</th> <th style="width: 10%;">Cable Length</th> <th style="width: 15%;">Rolling Size (Single Cable)</th> <th style="width: 15%;">Polybag Type (Single Cable)</th> <th style="width: 15%;">Bag Size (Single Cable)</th> <th style="width: 15%;">Article Weight (Single Cable)</th> </tr> <tr> <td>AK-330107-100-S</td> <td>10.0m</td> <td>170±10mm</td> <td>Ordinary Polybag (Heat Sealed)</td> <td>330*300*0.05mm</td> <td>0.532kg</td> </tr> </table>								P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)	AK-330107-100-S	10.0m	170±10mm	Ordinary Polybag (Heat Sealed)	330*300*0.05mm	0.532kg	B			
P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)																			
AK-330107-100-S	10.0m	170±10mm	Ordinary Polybag (Heat Sealed)	330*300*0.05mm	0.532kg																			
C	Carton Details <table border="1" style="width:100%; border-collapse: collapse; text-align: center;"> <tr> <th style="width: 15%;">P/N</th> <th style="width: 10%;">Cable Length</th> <th style="width: 10%;">Quantity (Carton)</th> <th style="width: 15%;">Measurement (Carton)</th> <th style="width: 10%;">N.W. (Carton)</th> <th style="width: 10%;">G.W. (Carton)</th> </tr> <tr> <td>AK-330107-100-S</td> <td>10.0m</td> <td>20 pcs</td> <td>38x38x22cm</td> <td>10.5kg</td> <td>10.9kg</td> </tr> </table>								P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)	AK-330107-100-S	10.0m	20 pcs	38x38x22cm	10.5kg	10.9kg	C			
P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)																			
AK-330107-100-S	10.0m	20 pcs	38x38x22cm	10.5kg	10.9kg																			
D						Single Cable		D																
E									E															
F									F															
G	☆ * "ROTTERDAM" is for Sea Freight shipment * "COLOGNE" is for Air Freight shipment * "LUDENSCHIED" is for Fedex or UPS shipment					<table border="1" style="width:100%; border-collapse: collapse; font-size: 0.8em;"> <tr> <th style="width: 15%;"></th> <th style="width: 15%;">Date</th> <th style="width: 15%;">Name</th> <th style="width: 55%;">Part No.</th> </tr> <tr> <td>Drawn by</td> <td>May.10,2017</td> <td>Achy</td> <td>AK-330107-100-S</td> </tr> <tr> <td>Checked by</td> <td>May.10,2017</td> <td>Helen</td> <td>EAN:4016032307051</td> </tr> <tr> <td>Approved by</td> <td>15May, 2017</td> <td>Joe</td> <td></td> </tr> </table>			Date	Name	Part No.	Drawn by	May.10,2017	Achy	AK-330107-100-S	Checked by	May.10,2017	Helen	EAN:4016032307051	Approved by	15May, 2017	Joe		G
						Date	Name	Part No.																
Drawn by	May.10,2017	Achy	AK-330107-100-S																					
Checked by	May.10,2017	Helen	EAN:4016032307051																					
Approved by	15May, 2017	Joe																						
H						ASSMANN Electronic GmbH <table border="1" style="width:100%; border-collapse: collapse; font-size: 0.7em;"> <tr> <th style="width: 30%;">Title</th> <th style="width: 30%;">Scale</th> <th style="width: 20%;">N/A</th> <th style="width: 20%;">Sheet</th> </tr> <tr> <td>HDMI High Speed connection cable,type A M/M,10.0m,w/Ethernrt,Ultra HD 24p, bl,gold</td> <td>Unit</td> <td>MM</td> <td>1/2</td> </tr> </table>		Title	Scale	N/A	Sheet	HDMI High Speed connection cable,type A M/M,10.0m,w/Ethernrt,Ultra HD 24p, bl,gold	Unit	MM	1/2	H								
Title	Scale	N/A	Sheet																					
HDMI High Speed connection cable,type A M/M,10.0m,w/Ethernrt,Ultra HD 24p, bl,gold	Unit	MM	1/2																					
	1	2	3	4	5	6	7																	