


Measuring leads

MLB 100/1 V

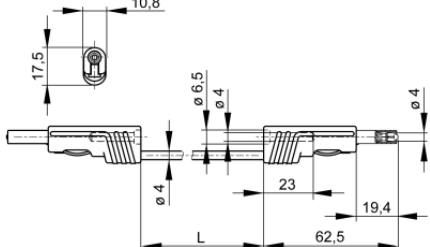

Product	MLB 100/1 V
description	Contact protected test lead on both sides sprung plug Ø 4 mm, insulated by latching and sprung insulated, which is only released by pressure on the lateral locking spring, and rigid socket Ø 4 mm to the far pluginess. Highly flexible, double insulated stranded conductor with integrated color indicator for detecting damage to the insulation.
operating instruction	BA401
article-no. / *colour	9736461xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green ● 88 yellow green ● 07 white
drawing	
	
technical data	
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	16 A
material socket	contact pin: brass contact spring: copper - beryllium
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-15 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2
cable length	100 cm

4 mm sliding sleeve system

conductor size	1 mm ²
cable material	PVC

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 21.06.2022

stand: 21.06.2022