


Measuring leads

MLS SIL GG 200/1

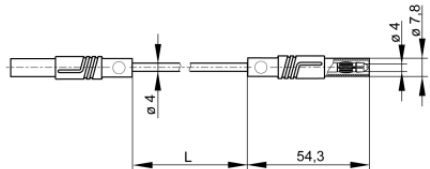

Product	MLS SIL GG 200/1
description	Safety silicone measuring lead, at either end 4 mm diameter safety connector with straight outlet. Nickel-plated copper beryllium contact spring. Highly flexible, double insulated stranded lead, high-temperature resistant, shatter-proof grip sleeve and lead. Built in colour indicator for easy identification of insulation damages.
operating instruction	BA453
article-no. / *colour	9341761xx  00 black  01 red  02 blue  03 yellow  04 green  88 yellow green Ni
drawing	
	
technical data	
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	16 A
material plug	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-15 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2
cable length	200 cm
conductor size	1 mm ²

4 mm safety system

cable material	SIL
----------------	-----

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 21.06.2022

stand: 21.06.2022