

1550 & 1350 Hi-Inrush Switches 150A to IEC65 and 16A 250Vac



1550 Series

16(4)A 250Vac T125

UL CSA 16A 250Vac

UL CSA (2 position) 250Vac 1hp, 125Vac ½hp

UL CSA (3 position) 250Vac ½hp, 125Vac ¼hp

Inrush 36A to EN61058-1 & 20A 28Vdc (In house tests)

1350 Hi Inrush Series

© 150A Inrush to IEC 65

16(4)A 250Vac T85 1E4 (10,000 Operations)

UL CSA 20A 250Vac


UL CSA 250Vac 1hp, 125Vac ½hp

UL 85°C, file E45221

CSA file LR10990

20A 28Vdc (In house test)

3mm contact gap except where marked μ.

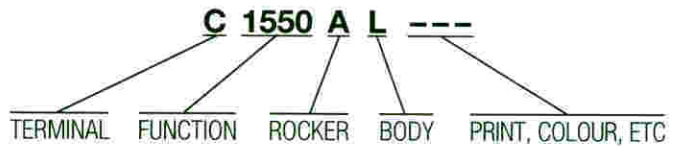


TERMINAL CODE	SWITCH FUNCTION CODE		ROCKER CODE
C 	<i>Approvals & ratings vary with function</i> <i>On Off Switches are On when pressed over terminal 1</i>		A Softline
H 	Standard 1550 ♦	High inrush 1350 ♦	V Curved
K 	1551 HP Rating N/A	ON - OFF 16(6)A T125 5E4 available on request	N Slimline sub-panel rocker
T 	1552 HP Rating N/A	ON - OFF (momentary ON)	P Lit window
X 	1553 ♦	1353 ♦	X Softline 2 Colour Rocker
	1560 ♦ μ	ON - ON	A Softline
	1561 μ HP Rating N/A	ON - ON (momentary 1 side)	
	1570 ♦ μ 250V 1/2HP 125V 1/4HP H terminal is rated T100 only	ON - OFF - ON	
	1571 μ HP Rating N/A H terminal is rated T100 only	ON - OFF - ON (momentary 1 side)	
	1572 μ HP Rating N/A H terminal is rated T100 only	ON - OFF - ON (momentary 2 sides)	
	5A ONLY *1484 μ Further circuits available	OFF - A - A+B Selective other circuits available	
	0480 X terminal N/A	Indicator	

Most switches shown can be supplied with single pole switching in double pole bodies



BODY CODE	
Panel cut-outs*	Flanges
A Gloss or Matt	 30.2 25.0
B Matt only	 33.4 25.0
L Matt only	 32.0 25.0
Q Gloss or Matt	 30.2 25.0
R Matt only	 33.2 28.9
T Matt only	 30.2 25.0

DIMENSIONS

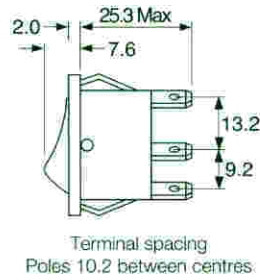

Panel thickness

- A,Q** 0.75 to 3.3mm
- L,B,T** 0.75 to 2.5mm
- R** 0.75 to 3.0mm

Moisture resistant covers (IP65)

Snap on to A, L, Q or T bodies (add G after body code). A panel sealing washer W42 is also available for certain body sizes. Covers or washers reduce panel thickness range & are not suitable for momentary types.



* Momentary Switches Panel cut-outs

Contact our Sales department for advice on cut-out sizes.

Examples of printing



EN602A



EN1091



EN822



EN722



EN727



EN730