


2000 Slide Switches

10A 250Vac

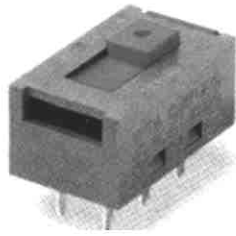

6(3)A, 10A 250Vac T85

UL CSA 16A 250Vac Non Inductive

UL CSA 4A 300Vac


UL65°C, file no. E45221, CSA file no. LR10990

μ contact gap

X 2 2 20 0 C AAF

TERMINAL SERIES POSITIONS CIRCUIT SLIDER BODY PRINT, COLOUR, ETC

▷ **TERMINAL CODE**

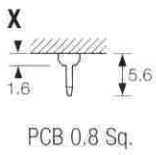

▷ **SERIES CODE**

2

▷ **POS'N CODE**

2 ◆
Switching positions


▷ **CIRCUIT CODE**
Viewed from back

20




▷ **SLIDER CODE**

5

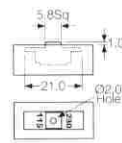


▷ **BODY CODE**

 C 2 positions



DIMENSIONS (mm)

2 Position C body

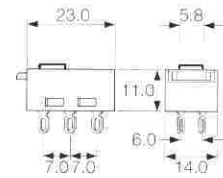

Cut-out / Matrix

