


\* The specification subject to change without notice. "The drawing is for reference only.

## R13-527

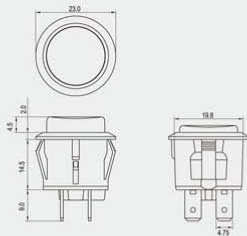

PATENT

FAUS

### Rating

10A 125V/5A 250V AC  
1/2HP 125V-250V AC

### Contact resistance

50mΩ Max

### Insulation resistance

DC 500V 100MΩ Min

### Dielectric strength

AC 1000V 1 minute

### Cut-out



cut-out 0.7-3.0 mm max

### FEATURES


- \* MATERIAL: Frame is nylon (UL flame:94V-2). Terminals are silver plated brass.
- \* Illuminated actuators are molded in PC, available with red, amber, green, blue and white colors.
- \* Snap-in mounting, easy to install switch into panel.
- \* Water proof and dust proof to fit IP-65.

### Cut-out for X2 BUTTON


 
 
 

 
 
 

 
 
 
 
 
 
 
 

 

 


cut-out 0.7-2.5 mm max

### BUTTON

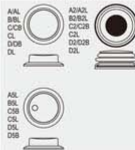

R13-527  - 

FUNCTION		TERMINAL		
Non-illuminated button (不帶燈)		0 2  .187" SQ		
<b>B</b>	<b>D</b>			
				
Illuminated / Different button (帶燈/按鈕不同)				
<b>B L</b>	<b>B 5 L</b>	<b>D 5 B</b>		
				
Momentary / Non-illuminated button (彈回/不帶燈)				
<b>A</b>	<b>C</b>			
				
Momentary / Non-illuminated / Different button (彈回/不帶燈/按鈕不同)				
<b>A L</b>	<b>A 5 L</b>	<b>C B</b>	<b>C 5 B</b>	
				
Independent circuit (獨立電路)				
<b>C L</b>	<b>C 5 L</b>	<b>D L</b>	<b>D 5 L</b>	
				
Waterproof (防水)				
<b>A 2</b>	<b>A 2 L</b>	<b>B 2</b>	<b>B 2 L</b>	<b>C 2</b>
				
<b>C 2 B</b>	<b>C 2 L</b>	<b>D 2</b>	<b>D 2 B</b>	<b>D 2 L</b>
