

Datasheet


Item no. 701287

V1_0717_01_en

Anti-vandal Water-proof Metal Push Button



- ⊙ Φ 16mm Diameter
- ⊙ Switch Rating:2A/36VDC
- ⊙ Contact Configuration: 1NO
- ⊙ Operation Type: Momentary
- ⊙ Panel Thickness: 1~3mm
- ⊙ The Crust Material(⊙) : Brass(Bronze-coloured) IP Degree: IP40,IK09

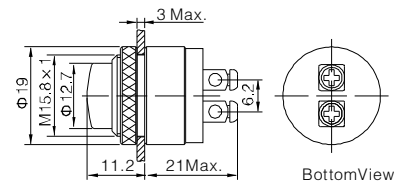

701287 : 16mm, Doorbell Push Button Switch, Material: Brass Crust , Inner G.W.:0.928kg, Inner Dim: 200x60x130mm, Exp G.W.: 24.1kg, Exp Dim: 500x370x290mm

701287		Material	Button	Brass(Bronze-coloured)
			Body	Brass(Bronze-coloured)
			Base	PBT
Terminal Type	Screw Terminal	Operation Pressure	About 8N	
Switching	X(double-break slow-motion contact)	Operation Travel	About 3mm	
Panel Thickness	1 ~ 3mm			
Torque	0.6Nm			
Mechanical Life	1,000,000 cycles			
Electrical Life	200,000 cycles	RoHS	Yes	

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.