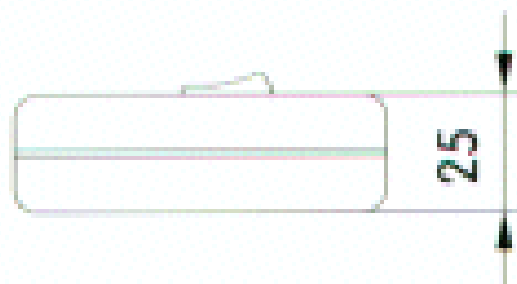
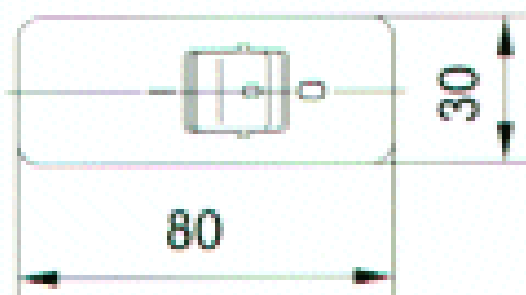

Data sheet

Article Description

Line intermediate switch Type 8010

10 (4) A, 250 V, **2-pole**, on/off-switch
screwed housing and strain relief,
protective earth terminal,
marking 0-I, screw terminals,
for cable 2 x 0,75 mm² + 3 x 0,75 mm²,

Article Picture



<i>inter BÄR-No.</i>	<i>colour housing</i>	<i>rocker</i>	
8010-004.01	black	red	
8010-008.01	white	white	
8010-009.01	brown	brown	
8010-000.01	transparent	transparent	
8010-020.01	titan	titan	
8010-104.01	black	red	illuminated
8010-108.01	white	red	illuminated

Technical modifications reserved!

Works at 230 V-mains must only be carried out by a specialist!