

DATA SHEET

B/N 703133
MS-500 M-BC Toggle Switch

Specifications :

Rating : 6A.125V. AC

Circuit : ON-ON 3PDT (9 Pin)

Contact Resistance : 20mΩ or less,
 initial characteristics


Insulation Resistance : DC500V Megger.
 100MΩ or more

Dielectric Strength : 1000V,AC (Between terminals)
 1500V, AC
 (Between Live metal parts and
 dead metal parts) 50/60Hz for
 1minute

Durability : Rated load with Resistance, 5,000 cycles
 Non-load, 30,000 cycles

Construction :

	Materials	Finish
① Cap	Vinyl Chloride	Black
② Lever	Brass	Chrome Plated
③ Metal	Brass	Nickel Plated
④ Hex Nut	Steel	Nickel Plated
⑤ Lock Washer	Steel	Unichromate
⑥ Locking Ring	Steel	Unichromate
⑦ Frame	Stainless Steel	Cleaning
⑧ Body	Melamine Phenolic	Blue
⑨ Terminal	Silver Clad Copper	Silver Plated
⑩ Common Terminal	Copper	Silver Plated

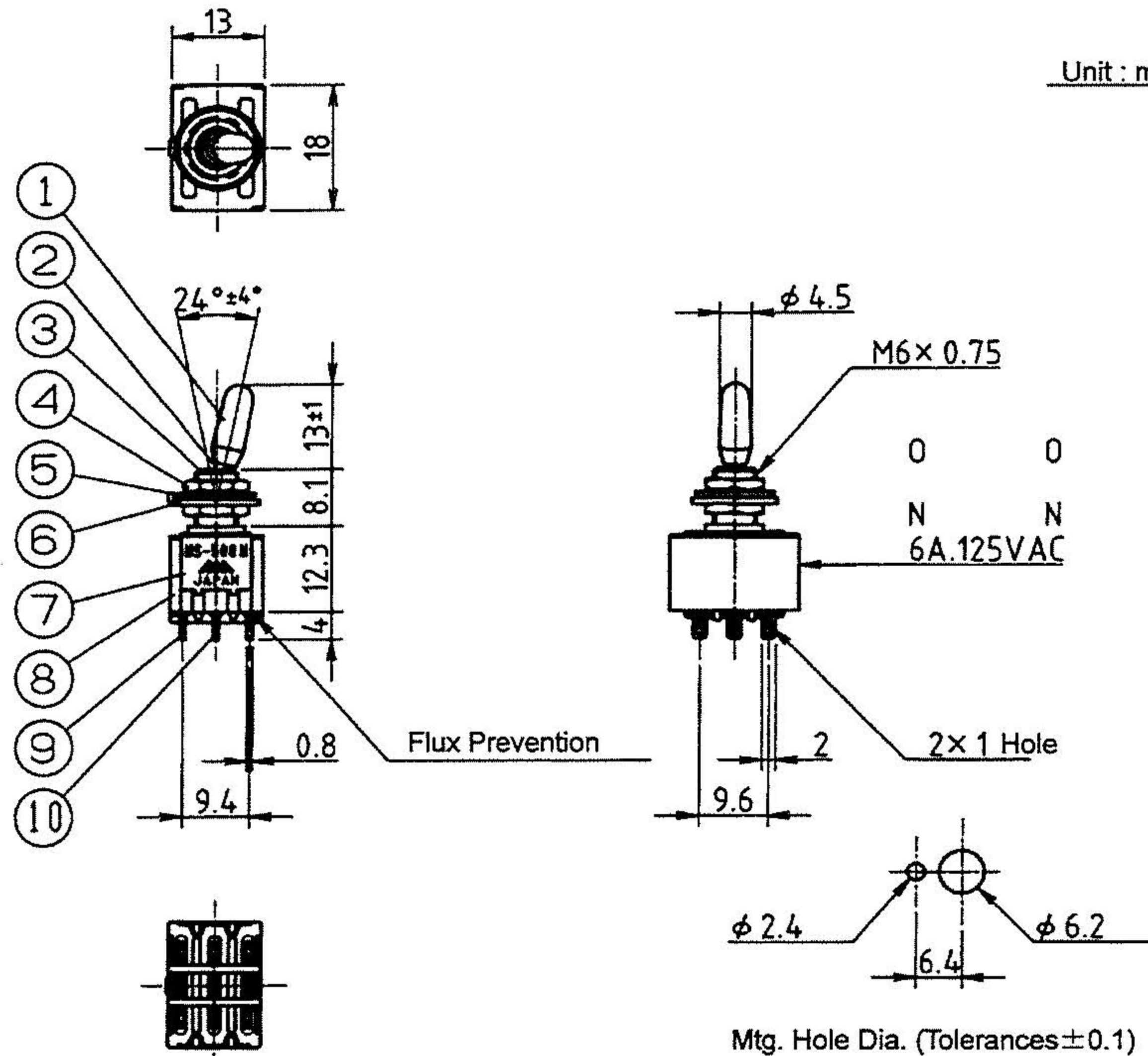

MIYAMA ELECTRIC CO., LTD. TOKYO JAPAN