

# DATA SHEET

Model No.  
 DS-850K-F1- LR (Red LED)  
 LG (Green LED)

Rocker Switch

Specifications :

Rating : 5A.125V. AC  
 3A.250V. AC

Circuit : OFF-ON SPST

Contact Resistance : 20mΩ or less


Insulation Resistance : DC500V Megger  
 100MΩ or more

Voltage Breakdown : AC2000V (1 minute)

Construction :

|                     | Materials       | Finish      |
|---------------------|-----------------|-------------|
| ① Knob              | PA              | Black, Grey |
| ② Case              | PA              | Black, Grey |
| ③ Terminal (A)      | Copper          | Ep-Cu/Ag    |
| ④ Terminal (B)      | Copper          | Ep-Cu/Ag    |
| ⑤ Base              | PF              | Black       |
| ⑥ Terminal for Lamp | Phosphor Bronze | Ep-Cu/N1    |
| ⑦ Transparent plate | Acrylic Resin   | Red, Green  |

Unit : mm

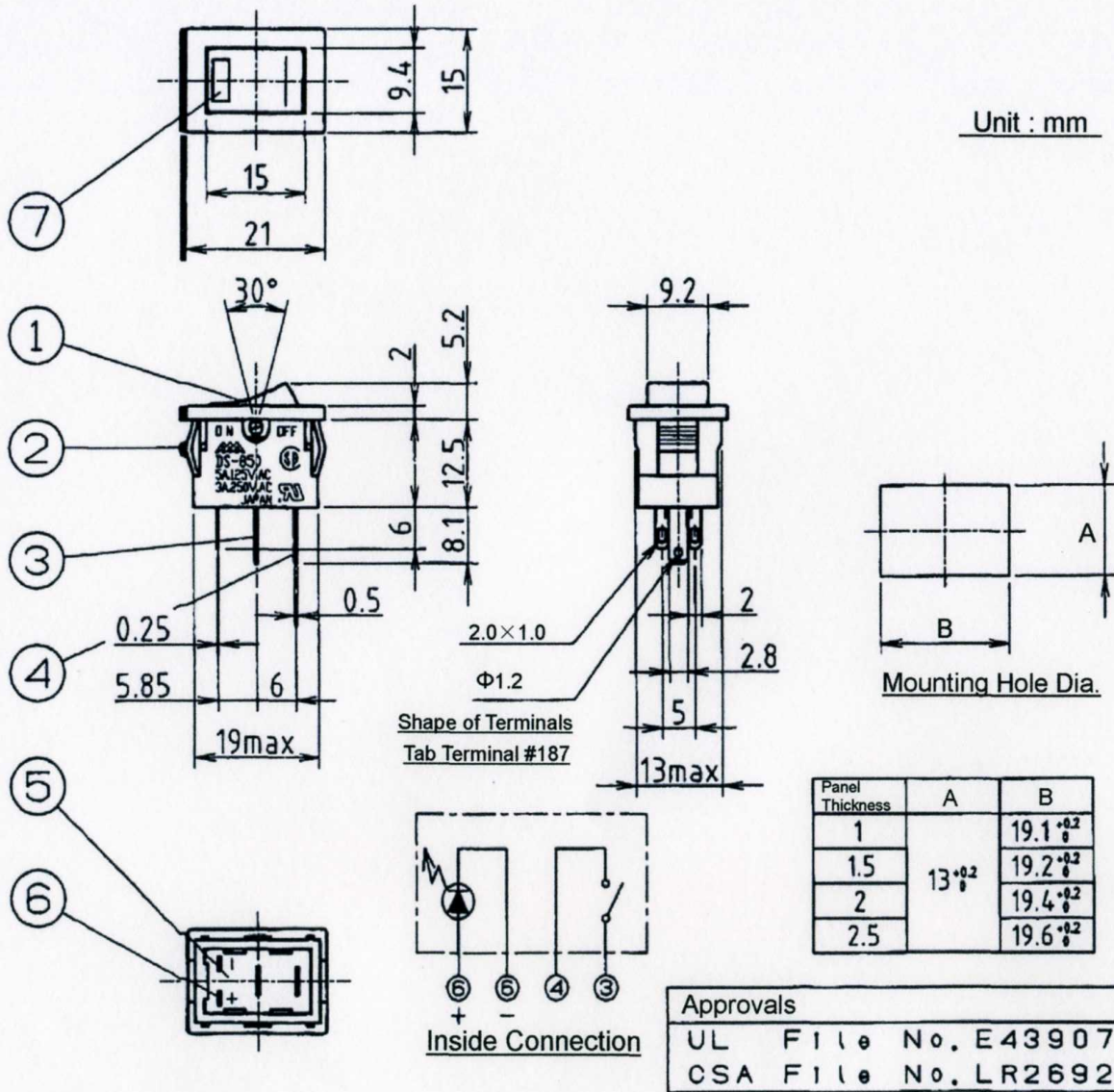

| Panel Thickness | A                  | B                    |
|-----------------|--------------------|----------------------|
| 1               | 13 <sup>+0.2</sup> | 19.1 <sup>+0.2</sup> |
| 1.5             |                    | 19.2 <sup>+0.2</sup> |
| 2               |                    | 19.4 <sup>+0.2</sup> |
| 2.5             |                    | 19.6 <sup>+0.2</sup> |

Approvals  
 UL File No. E43907  
 CSA File No. LR26920