

Complete switch disconnectors 25 to 100 A


IP 40 as standard, IP 65 on request

 Characteristics (p. 306)

FRONT MOUNTING

PADLOCKABLE PRESENTATION

Cat. No.

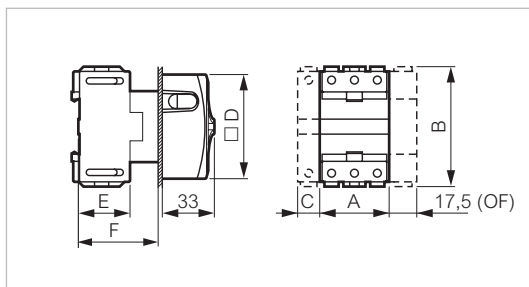

Safety switch to disconnect and isolate poles.
 IP 20 "finger safe"
 Double break type load switching
 Red padlockable handle on yellow plate
 Actual position (ON or OFF) clearly visible
 Conform to standards:
 IEC EN 60947-3
 Approved by UL - cUL – Suitable as motor disconnect



172001

Dimensions	
A:	44
B:	75.4
C:	14.5
D:	□ 66
E:	36
F:	50

25 A	
3P	172001
3P+NC/NO (1)	172011
4P neutral on left	172021

32 A	
3P	172101
4P neutral on left	172121



172201

Dimensions	
A:	53.6
B:	85
C:	17.9
D:	□ 66
E:	50.3
F:	60

50 A	
3P	172201
4P neutral on left	172221

63 A	
3P	172301
4P neutral on left	172321



172401

Dimensions	
A:	71.8
B:	93
C:	26.8
D:	□ 86
E:	63.8
F:	70

80 A	
3P	172401
4P neutral on left	172421

100 A	
3P	172501

(1) Padlock: \varnothing 6 to 8 mm