

# Complete switch disconnectors 25 to 100 A


IP 40 as standard, IP 65 on request

 Characteristics (p. 306)

## FRONT MOUNTING

### PADLOCKABLE PRESENTATION

Cat. No.

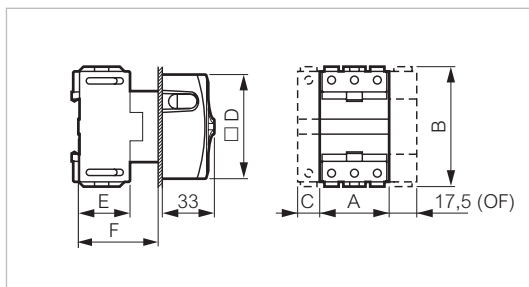

Safety switch to disconnect and isolate poles.  
 IP 20 "finger safe"  
 Double break type load switching  
 Red padlockable handle on yellow plate  
 Actual position (ON or OFF) clearly visible  
 Conform to standards:  
 IEC EN 60947-3  
 Approved by UL - cUL – Suitable as motor disconnect



172001

Dimensions	
A:	44
B:	75.4
C:	14.5
D:	□ 66
E:	36
F:	50

<b>25 A</b>	
3P	<b>172001</b>
3P+NC/NO (1)	<b>172011</b>
4P neutral on left	<b>172021</b>

<b>32 A</b>	
3P	<b>172101</b>
4P neutral on left	<b>172121</b>



172201

Dimensions	
A:	53.6
B:	85
C:	17.9
D:	□ 66
E:	50.3
F:	60

<b>50 A</b>	
3P	<b>172201</b>
4P neutral on left	<b>172221</b>

<b>63 A</b>	
3P	<b>172301</b>
4P neutral on left	<b>172321</b>



172401

Dimensions	
A:	71.8
B:	93
C:	26.8
D:	□ 86
E:	63.8
F:	70

<b>80 A</b>	
3P	<b>172401</b>
4P neutral on left	<b>172421</b>

<b>100 A</b>	
3P	<b>172501</b>

(1) Padlock:  $\varnothing$  6 to 8 mm