


Separate units \varnothing 22: Heads

IP 66
 To be combined with a clip, LED block and contact blocks (p. 48)
 With locking ring
 Plastic chrome bezel - Black bezel on request (form p. 79)
 Conform to IEC 60947-5-1

 Characteristics (p. 94)
 Cross reference list (p. 311)


► PUSH-BUTTONS - ILLUMINATED (CONTINUED)

STAY-PUT - FLUSH

Réf.



L21CH20

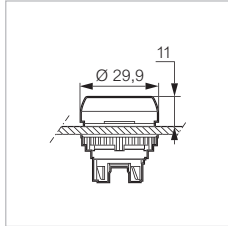


- Red
- Green
- Yellow
- White
- Blue

- L21CH10**
- L21CH20**
- L21CH40**
- L21CH50**
- L21CH60**

STAY-PUT - SUPER FLUSH



L23CH10

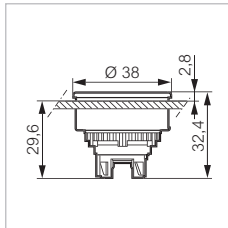

Metallic chrome bezel
 Drilling \varnothing 30 mm


- Red
- Green
- Yellow
- White
- Blue

- L23CH10**
- L23CH20**
- L23CH40**
- L23CH50**
- L23CH60**

STAY-PUT - PROJECTING



L21CK20

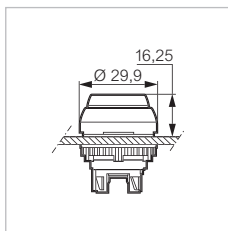

- Red
- Green
- Yellow
- White
- Blue

- L21CK10**
- L21CK20**
- L21CK40**
- L21CK50**
- L21CK60**