

Cam switches

 Characteristics (p. 203)

► 3-WAY CAM SWITCHES WITH “OFF” POSITION (CONTINUED)

PR 12 - 16 A (AC21)

2-screw panel mount – interval: 30 mm

Cat. No.



ND03AQ1

Grey/black small handle
□ 48 aluminium plate and frame


Designation

1P - 3 contacts
2P - 6 contacts
3P - 9 contacts



PR12 2301 A4 E Q48PN
PR12 2302 A4 E Q48PN
PR12 2303 A4 E Q48PN

ND01AQ1
ND02AQ1
ND03AQ1

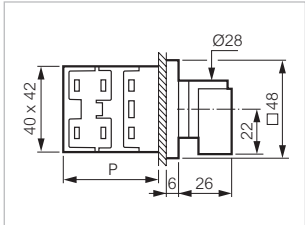

Dimensions in mm

*P: 46 (3 CONTACTS)
56 (6 CONTACTS)
76 (9 CONTACTS)

PR 12 - 16 A (AC21)

∅ 22 single hole front mounting

Cat. No.



ND02AX80

Grey/black small handle
□ 48 aluminium plate and frame


Designation

1P - 3 contacts
2P - 6 contacts
3P - 9 contacts



PR12 2301 A4 E N48MD50
PR12 2302 A4 E N48MD50
PR12 2303 A4 E N48MD50

ND01AX80
ND02AX80
ND03AX80

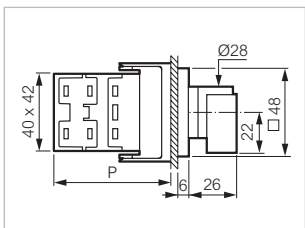

Dimensions in mm

*P: 61 (3 CONTACTS)
71 (6 CONTACTS)
91 (9 CONTACTS)

*P = Depth