

# Separate units $\varnothing$ 30: Heads

IP 65

To be combined with a clip and electrical blocks (p. 48)

With locking ring

Plastic chrome bezel- Other bezel on request (form p. 117)

$\varnothing$  30 blocks use the same blocks and clips (except for the 5 position clip) as  $\varnothing$  22 mm heads (see p. 48-65)

Conform to IEC 60947-5-1



Characteristics (p. 121)


## ► PUSH-BUTTONS - NON ILLUMINATED

### SPRING RETURN - FLUSH

Cat. No.



T16AA01

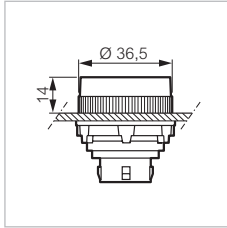

#### Without engraving

- Red
- Green
- Black
- Yellow
- White
- Blue

- T16AA01
- T16AA02
- T16AA03
- T16AA04
- T16AA05
- T16AA06

#### With engraving

- ⦿ Red
- ⦿ Green
- ⦿ Black


- T16AA81
- T16AA82
- T16AA83

### SPRING RETURN - FLUSH

Reinforced degree of protection: IP 67



T12AG03

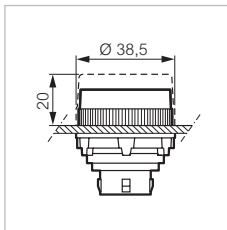

Supplied with transparent shroud  
Marking possible  
(engravings and symbols p. 118 and p. 72)


- Red
- Green
- Black
- Yellow
- White
- Blue

- T12AG01
- T12AG02
- T12AG03
- T12AG04
- T12AG05
- T12AG06

### SPRING RETURN - PROJECTING



T16AB01

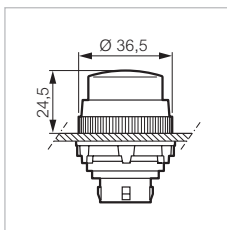

- Red
- Green
- Black
- Yellow
- White
- Blue

- T16AB01
- T16AB02
- T16AB03
- T16AB04
- T16AB05
- T16AB06