


Separate units \varnothing 22: Heads

IP 66
 To be combined with a clip and electrical blocks (p. 48)
 With locking ring
 Plastic chrome bezel- Black bezel on request (form p. 79)
 Conform to IEC 60947-5-1

 Characteristics (p. 94)
 Cross reference list (p. 311)

▶ SELECTOR SWITCHES - NON ILLUMINATED (CONTINUED)


WITH KEY

3 positions

Cat. No.



L21NA00

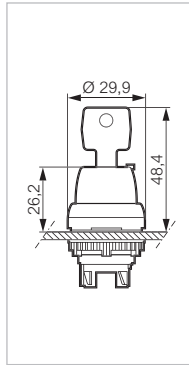

Key free in position:

Supplied with 2 keys profile n° 455

Stay-put positions - 45°

● Black



0

L21NA00

Spring return from left to 0 - 45°

● Black



0

L21NB00

Spring return from right to 0 - 45°

● Black



0

L21NC00

Spring return to 0 - 45°

● Black



0

L21ND00

Stay-put positions - 45°

● Black



1 - 2

L21NE00

Spring return from right to 0 - 45°

● Black



1

L21NJ00

Stay-put positions - 90°

● Black



1 - 0 - 2

L21NK00

Stay-put positions - 90°

● Black



0

L21NL00

Key profile n° 1424 A and others (form p. 79)