


Separate units \varnothing 22: Heads

IP 65
 With locking ring
 Plastic chrome bezel
 Black bezel on request (form p. 79)
 Conform to IEC 60947-5-1

 Characteristics (p. 94)
 Cross reference list (p. 311)


► ADJUSTABLE MECHANICAL PUSH/RESET BUTTON - NON ILLUMINATED

SPRING RETURN - FLUSH

Cat. No.



L21HA01

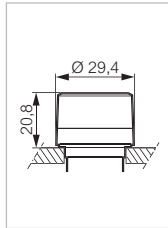

To be used without electrical block
 Stroke 11 mm
 Adjustable: 26 mm min to 46 mm max / front side of panel

Without engraving

- Red
- Green
- Black
- Yellow
- White
- Blue

- L21HA01**
- L21HA02**
- L21HA03**
- L21HA04
- L21HA05
- L21HA06**

On demand engraving (p. 79)

Symbol code to be added at the end of the catalogue number


- Red
- Green
- Black
- Yellow
- White
- Blue

- L21HA31□□□□
- L21HA32□□□□
- L21HA33□□□□
- L21HA34□□□□
- L21HA35□□□□
- L21HA36□□□□

SPRING RETURN - PROJECTING



L21HB06

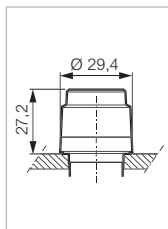

To be used without electrical block
 Stroke 11 mm
 Adjustable: 26 mm min to 46 mm max / front side of panel

- Red
- Green
- Black
- Yellow
- White
- Blue

- L21HB01**
- L21HB02**
- L21HB03**
- L21HB04
- L21HB05
- L21HB06**