

Separate units \varnothing 30: Heads

IP 65

To be combined with a clip and electrical blocks (p. 48)

With locking ring

Plastic chrome bezel - Other bezel on request (form p. 117)

\varnothing 30 blocks use the same blocks and clips (except for the 5 position clip) as \varnothing 22 mm heads (see p. 48-65)

Conform to IEC 60947-5-1




Characteristics (p. 121)

► MUSHROOM HEADS - NON ILLUMINATED

\varnothing 40 - STAY-PUT

Push-pull to reset

Cat. No.

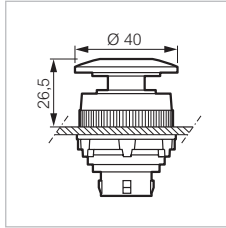


- Red
- Green
- Black
- Yellow

- T16DD01
- T16DD02
- T16DD03
- T16DD04

T16DD01

\varnothing 40 - STAY-PUT

Push-turn to reset

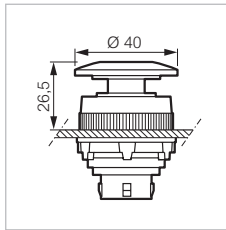

Stay-put

- Red
- Green
- Black
- Yellow

- T16ED01
- T16ED02
- T16ED03
- T16ED04

T16ED01



Manual locking

- Red
- Green
- Black
- Yellow

- T16FD01
- T16FD02
- T16FD03
- T16FD04

\varnothing 40 - STAY-PUT

Key to reset

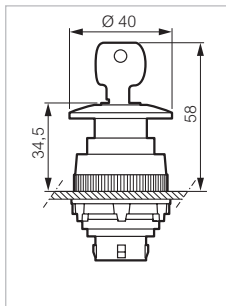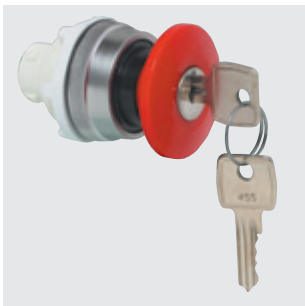

Supplied with 2 keys profile n° 455


- Red

T16GM01

T16GM01

\varnothing 70 - STAY-PUT

Key to reset

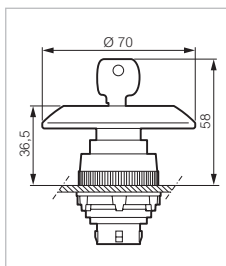

Supplied with 2 keys profile n° 455

- Red

T16GP01

T16GP01