

MP86 Dip Pushbutton Switches (W/LED, Transparent Cap)




SPECIFICATION:


CIRCUIT : SPDT
 CURRENT RATING : 12mA.
 VOLTAGE RATING : 24VDC.
 TEST VOLTAGE CONT-CONT : 150V.
 CONTACT RESISTANCE : 50mΩ Max.(initial)
 INSULATION RESISTANCE : 100MΩ Min.
 OPERATING FORCE : 170gf ± 50gf
 TOTAL TRAVEL : 2.5mm ± 0.2mm
 OPERATING LIFE : 500,000 CYCLES Min.
 SOLDER SPECIFICATIONS : 256°C for 5 seconds
 FUNCTION : Momentary
 OPERATING TEMPERATURE : +10°C ~ +60°C

MATERIALS:


CAP : ABS
 CASE : Nylon
 FIXED CONTACT : PBS+Au
 MOVING CONTACT : PBS+Au

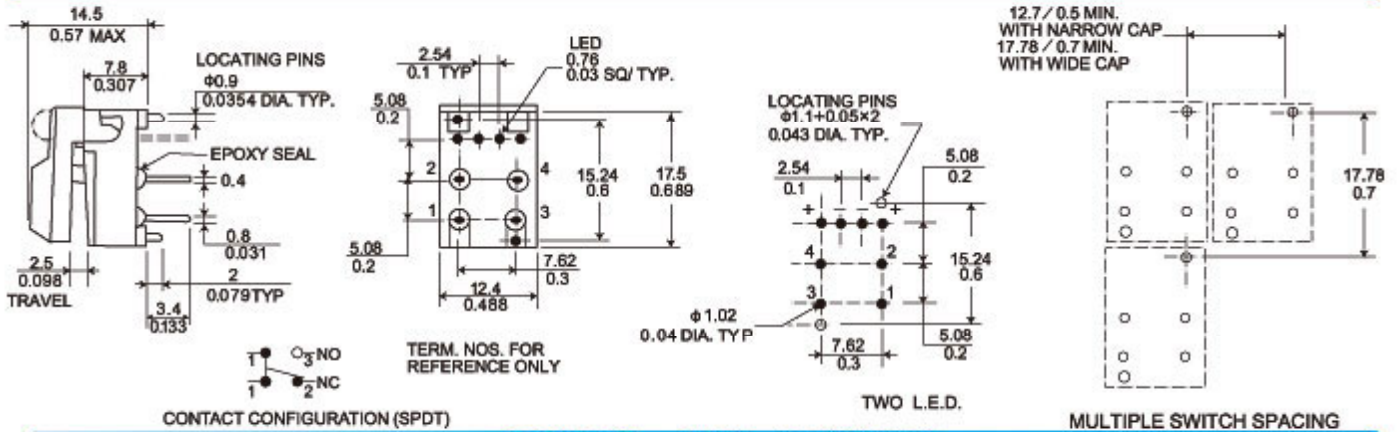

COLOR CAP STYLES

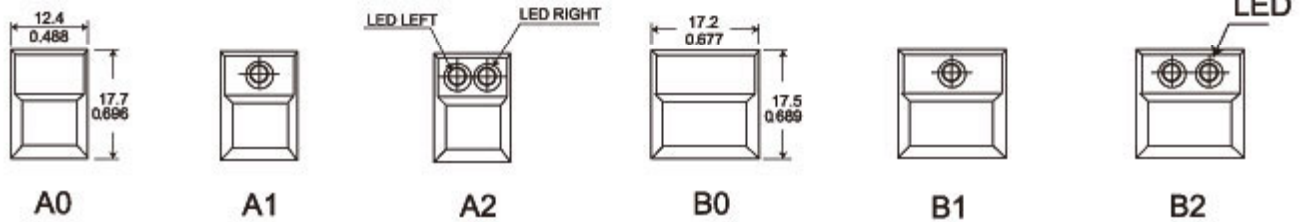

TRANSPARENT CAP STYLES

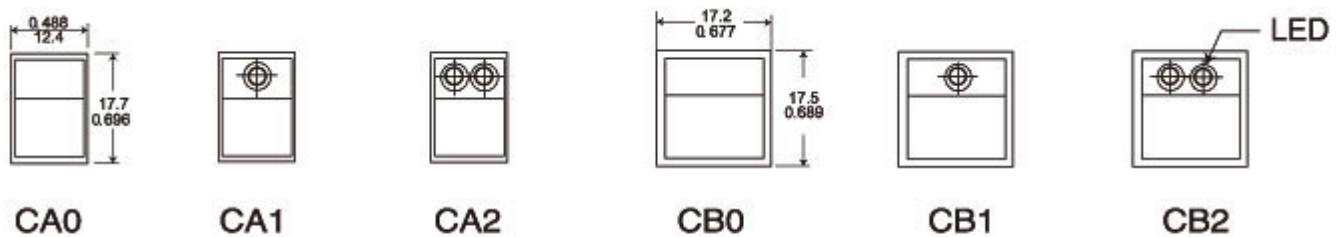

HOW TO ORDER

MODEL NO.	+	CAP STYLE	+	CAP OR CARD COLOR	+	LED COLOR LEFT	+	LED COLOR RIGHT
MP86		A0 CA0		R: RED BU: BLUE		□: WITHOUT LED		□: WITHOUT LED
		A1 CA1		G: GRAY GN: GREEN		1: RED		1: RED
		A2 CA2		B: BLACK BR: BROWN		2: YELLOW		2: YELLOW
		B0 CB0		W: WHITE		3: GREEN		3: GREEN
		B1 CB1		Y: YELLOW				
		B2 CB2		O: ORANGE				