

AL-28SW12-PT (Artikel-Nr. 710125-07)

EKULIT


SPECIFICATIONS:

| TYPE | UNIT | AL-28SW12-PT |
|-----------------------------|-----------------|--------------|
| • Min. Sound Output at 30cm | dB | 85 |
| Rated Voltage | V _{DC} | 12 |
| Operating Voltage | V _{DC} | 8~15 |
| Resonant Frequency | Hz | 2900±300 |
| • Max. Current Consumption | mA | 15 |
| Operating Temperature | °C | -20~+60 |
| Storage Temperature | °C | -30~+70 |
| Weight | g | 10 |

• Value applying at rated voltage DC

DIMENSIONS :

(Unit: mm)

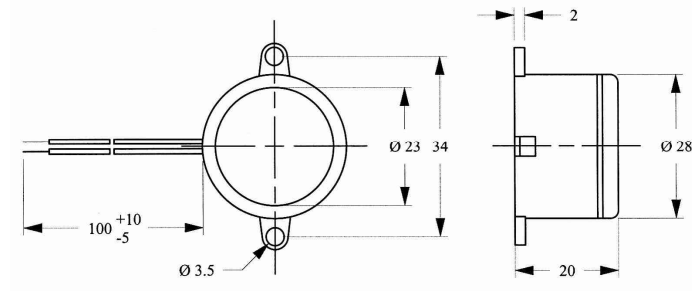

Frequency response:

