


LSM-S30K/P (Artikel-Nr. 710217)**EKULIT**

SPECIFICATIONS:

TYPE	UNIT	LSM-S30K/P
Impedance	Ω	$8 \pm 15\%$
Power (Nominal)	W	2.0
Power (Maximum)	W	4.0
Resonant Frequency	Hz	$380 \pm 20\%$
Sound Pressure Level	dB	84 ± 3
Frequency Range	Hz	Fo~20.000
Operating Temperature	°C	-20~+60
Storage Temperature	°C	-30~+70

DIMENSIONS :

(Unit: mm)

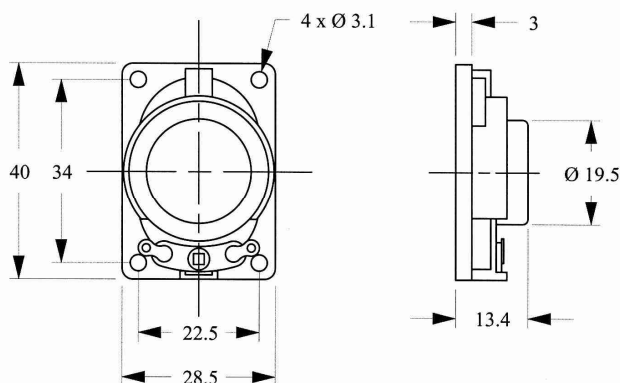

Frequency response:

