


# Technical datasheet: KPI-G4513L-K6314

## Specifications:


Operating Temperature	-20°C to +60°C
Storage Temperature	-30°C to +70°C
Rated Voltage	12VDC
Operating Voltage	3VDC to 16VDC
Max. Rated Current	35(20)mA at 12VDC
Resonant Frequency	3.2kHz $\pm$ 0.5kHz
Min SPL	92dB / 12VDC / 30cm
Weight	21g
Case Material/Color	ABS/White
Tone Nature	Continuous +Slow Pulse
Connection	RED(+12V) + BLACK: continuous tone RED(+12V) + YELLOW: slow pulse tone

## Dimensions:

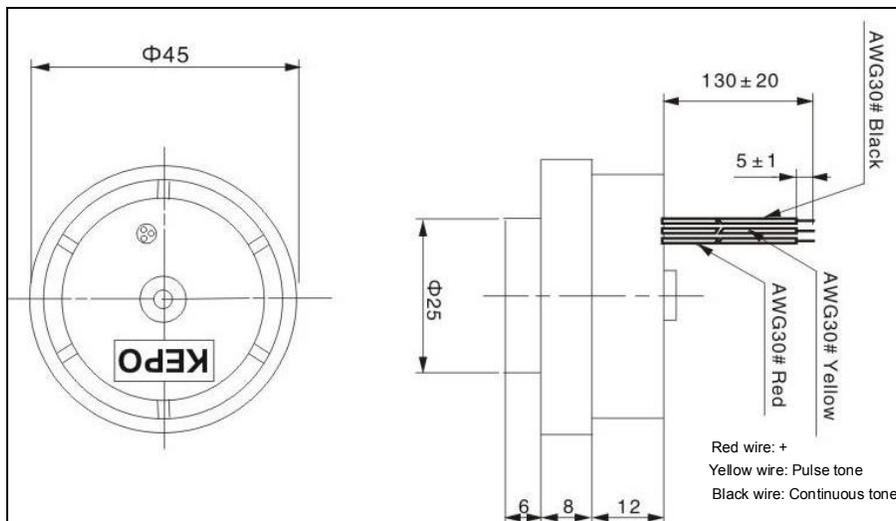

Input Signal:12VDC

S.P.L. Measuring Circuit

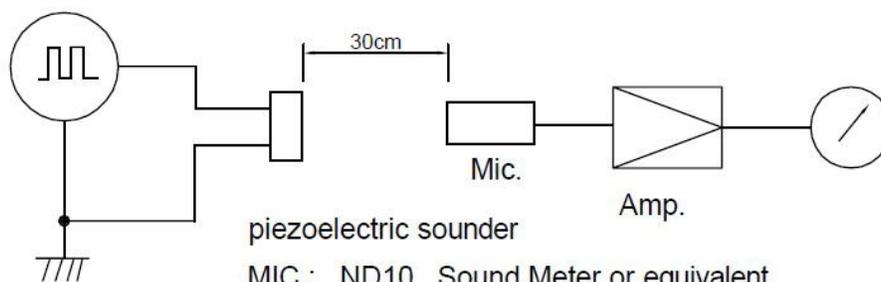

piezoelectric sounder

MIC : ND10 Sound Meter or equivalent

DC Power Supply : DF1730SL2A or equivalent

Frequency Response:

