


## Technical datasheet: KPI-G4514L-K6315

### Specifications:

Operating Temperature	-20°C to +60°C
Storage Temperature	-30°C to +70°C
Rated Voltage	12VDC
Operating Voltage	3VDC to 16VDC
Max. Rated Current	35mA at 12VDC
Resonant Frequency	3.2kHz $\pm$ 0.5kHz
Min SPL	92dB / 12VDC / 30cm
Weight	21g
Case Material/Color	ABS/White
Tone Nature	Continuous +Fast Pulse
Connection	RED (+12V) + BLACK: continuous tone RED (+12V) + YELLOW: slow pulse tone

### Dimensions:

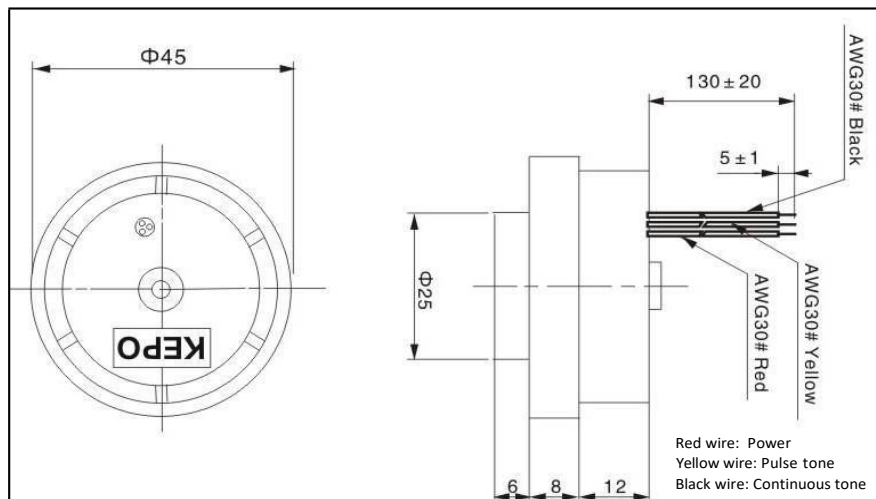

### Frequency Response:

