


Technical datasheet: KPMB-G2345L1(Notch)-K6412

Specifications:

Operating Temperature	-20°C to +60°C
Storage Temperature	-30°C to +70°C
Rated Voltage	4.5VDC
Operating Voltage	3V~6VDC
Max.Rated Current	30mA
Resonant Frequency	400Hz±100Hz
Min SPL	70dB at 4.5VDC/20cm
Response Time	50ms
Tone Nature	Continues
Weight	8g
Case Material/Color	ABS/Black

Dimensions:

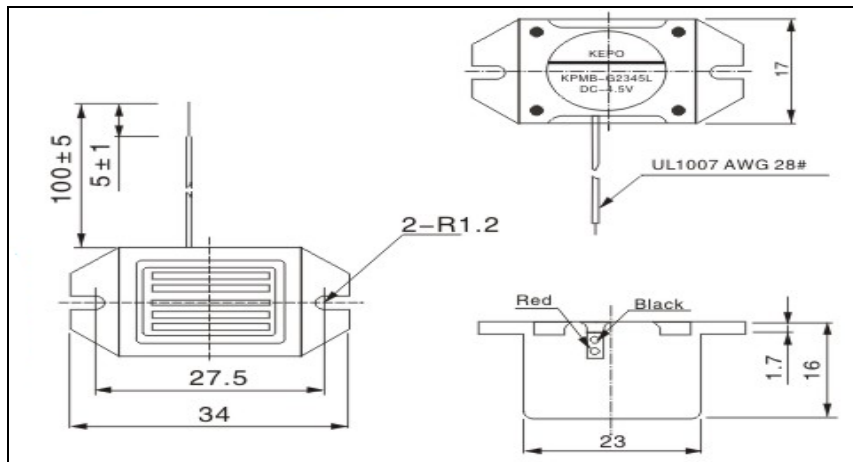

Frequency Response

