


## Technical datasheet: KPMB-G2309L1-K6410

### Specifications:

Operating Temperature	-20°C to +60°C
Storage Temperature	-30°C to +70°C
Rated Voltage	9VDC
Operating Voltage	6V~12VDC
Max.Rated Current	30mA
Resonant Frequency	400Hz±100Hz
Min SPL	75dB at 9VDC/20cm
Response Time	50ms
Tone Nature	Continues
Weight	10g
Case Material/Color	ABS/Black

### Dimensions:

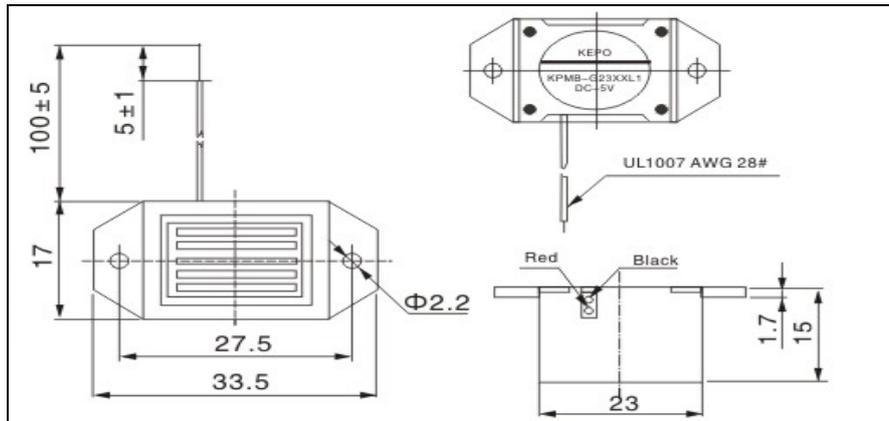

### Frequency Response

