


Test disconnect terminal block - UT 6-T-HV P/P - 3070121

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

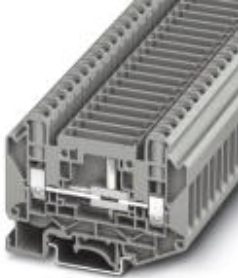

Test disconnect terminal block, Connection method: Screw connection, Cross section: 0.2 mm² -10 mm² , AWG: 24 - 8, Width: 8.2 mm, Mounting type: NS 35/7,5, NS 35/15, NS 32, Color: gray

Product Features

- ✓ The terminal block provides a function shaft on both sides of the disconnect point and can be fitted with plug-in bridges and test adapters with 4 mm diameter
- ✓ The KSS short-circuit plugs make contact either in the test adapter or the test socket screws of the terminal points
- ✓ The CARRIER 35-8 offers a parking option for KSS ... short-circuit plugs and FBS ... plug-in bridges
- ✓ Compact 1000 V test disconnect terminal block with screw disconnect slide

Key commercial data

package_quantity	50
GTIN	4046356545228

Technical data

General

Number of levels	1
Number of connections	2
Color	gray
Insulating material	PA
Inflammability class according to UL 94	V0

General

Maximum load current	57 A (with 10 mm ² conductor cross section)
Rated surge voltage	6 kV
Pollution degree	3
Surge voltage category	III
Insulating material group	I
Connection in acc. with standard	IEC 60947-7-1
Nominal current I _N	41 A
Nominal voltage U _N	1000 V
Open side panel	ja

Dimensions

Width	8.2 mm
Length	72.6 mm

Test disconnect terminal block - UT 6-T-HV P/P - 3070121

Technical data

Dimensions

Height NS 35/7,5	54.3 mm
Height NS 35/15	61.8 mm
Height NS 32	59.3 mm

Connection data

Note	Terminal point
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	10 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	8
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	10 mm ²
Min. AWG conductor cross section, stranded	24
Max. AWG conductor cross section, stranded	8
Conductor cross section stranded, with ferrule without plastic sleeve min.	0.25 mm ²
Conductor cross section stranded, with ferrule without plastic sleeve max.	6 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve min.	0.25 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve max.	6 mm ²
2 conductors with same cross section, solid min.	0.2 mm ²
2 conductors with same cross section, solid max.	2.5 mm ²
2 conductors with same cross section, stranded min.	0.2 mm ²
2 conductors with same cross section, stranded max.	2.5 mm ²
2 conductors with same cross section, stranded, TWIN ferrules with plastic sleeve, min.	0.5 mm ²
2 conductors with same cross section, stranded, TWIN ferrules with plastic sleeve, max.	4 mm ²
2 conductors with same cross section, stranded, ferrules without plastic sleeve, min.	0.25 mm ²
2 conductors with same cross section, stranded, ferrules without plastic sleeve, max.	1.5 mm ²
Connection method	Screw connection
Stripping length	12 mm
Internal cylindrical gage	A5
Screw thread	M4
Tightening torque, min	1.2 Nm
Tightening torque max	1.4 Nm

classifications

eCl@ss

eCl@ss 4.0	27141126
------------	----------

Test disconnect terminal block - UT 6-T-HV P/P - 3070121

classifications

eCl@ss

eCl@ss 4.1	27141126
eCl@ss 5.0	27141126
eCl@ss 5.1	27141126
eCl@ss 6.0	27141126
eCl@ss 7.0	27141126
eCl@ss 8.0	27141126

ETIM

ETIM 2.0	EC000902
ETIM 3.0	EC000902
ETIM 4.0	EC000902
ETIM 5.0	EC000902


UNSPSC

UNSPSC 6.01	30211811
UNSPSC 7.0901	39121410
UNSPSC 11	39121410
UNSPSC 12.01	39121410
UNSPSC 13.2	39121410

approvals

GOST /

 Approval details



accessories

Marker pen

X-PEN 0,35 - 0811228



Screwdriver tools

Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

SZG 0,9X6,5 VDE - 1205134



SZS 1,0X6,5 VDE - 1205079



SZS 1,0X4,0 VDE - 1205066



Short-circuit connector

KSS 8 - 0311540



KSS 4- 8 - 0309549



Partition plate

Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

ATP-URTK/SP - 0311139



Flange

CARRIER 35-8 - 3034387



Cover profile

AP-ME METER - 3034361



APH-ME - 3034374



APT-ME - 3034358



End cover

Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

D-UT 6-T-HV - 3070147



DP PS-8 - 3036741



Switching lock

S-UT 6-T-HV - 3070150



Bridge

FBS 2-8 - 3030284



FBS 3-8 - 3030297



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

FBS 4-8 - 3030307



FBS 5-8 - 3030310



FBS 10-8 - 3030323



FBS 6-8 - 3032470



FBS 1/3-8 - 3032363



FBS 1/4-8 - 3032376



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

FBS 1/3/5-8 - 3032389



FBS 1/4/7/10-8 - 3032402



SB-ME 2-8 - 3034468



SB-ME 3-8 - 3032800



SB-ME 4-8 - 3034484



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

FBS 1/5-8 - 3032381

FBSRH 2-8 - 3033802



FBSRH 3-8 - 3033803



FBSRH 4-8 - 3033804



FBSR 2-8 - 3033808



FBSR 3-8 - 3001597



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

FBSR 5-8 - 3033809



FBSR 10-8 - 3001599



FBSR 16-8 - 3033816



FBSR 1/6/11/16-8 - 3033820



FBSR 1/7/13/16-8 - 3033821



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

FBSR 1/6/11/14-8 - 3033822



Mounting rail

NS 32 PERF 2000MM - 1201002



NS 32 UNPERF 2000MM - 1201015



NS 35/ 7,5 PERF 2000MM - 0801733



NS 35/ 7,5 UNPERF 2000MM - 0801681



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

NS 35/ 7,5 WH PERF 2000MM - 1204119



NS 35/ 7,5 WH UNPERF 2000MM - 1204122



NS 35/ 7,5 AL UNPERF 2000MM - 0801704



NS 35/ 7,5 ZN PERF 2000MM - 1206421



NS 35/ 7,5 ZN UNPERF 2000MM - 1206434



NS 35/ 7,5 CU UNPERF 2000MM - 0801762



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

NS 35/ 7,5 CAP - 1206560



NS 35/15 PERF 2000MM - 1201730



NS 35/15 UNPERF 2000MM - 1201714



NS 35/15 WH PERF 2000MM - 0806602



NS 35/15 WH UNPERF 2000MM - 1204135



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

NS 35/15 AL UNPERF 2000MM - 1201756



NS 35/15 ZN PERF 2000MM - 1206599



NS 35/15 ZN UNPERF 2000MM - 1206586



NS 35/15 CU UNPERF 2000MM - 1201895



NS 35/15 CAP - 1206573



NS 35/15-2,3 UNPERF 2000MM - 1201798



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

Terminal marking

ZB 8:UNBEDRUCKT - 1052002



UC-TM 8 - 0818072



UCT-TM 8 - 0828740



Labeled terminal marker

ZB 8 CUS - 0825011



UC-TM 8 CUS - 0824597



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

UCT-TM 8 CUS - 0829616



Test plug terminal block

PAI-4-FIX BU - 3032729



PAI-4-FIX OG - 3034455



PAI-4-FIX YE - 3032745



PAI-4-FIX RD - 3032732



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

PAI-4-FIX GN - 3032758



PAI-4-FIX BK - 3032774



PAI-4-FIX GY - 3032790



PAI-4-FIX VT - 3032761



PAI-4-FIX BN - 3032787



PS-8 - 3031005



Test disconnect terminal block - UT 6-T-HV P/P - 3070121

accessories

PS-8/2,3MM RD - 3048564



End block

E/UK - 1201442



E/UK 1 - 1201413



Drawings

Circuit diagram

