

Sensor/Actuator cable - SAC-3P- 1,5-PUR/A-1L-Z - 1434989

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Sensor/Actuator cable, 3-position, PUR halogen-free, Black-gray RAL 7021, Free cable end, on Valve connector A, with 1 LED, connected with Z diode, Cable length: 1.5 m

Product Features

- Easy and safe: 100% electrically tested plug-in components
- Robust valve connector with Zener diode as protective circuit
- Convenient: increased machine availability thanks to quick and easy diagnostics
- Our standard: robust halogen-free PUR cable

Key commercial data

| | |
|-------------------------|---------------|
| package_quantity | 1 |
| GTIN | 4046356413367 |

Technical data

Dimensions

| | |
|---|-------|
| Length of cable | 1.5 m |
| Stripping length of the free conductor end | 50 mm |

Ambient conditions

| | |
|--|-------------------------------|
| Ambient temperature (operation) | -20 °C ... 85 °C (valve plug) |
| Degree of protection | IP65 |
| Degree of protection | IP67 |

General

| | |
|-------------------------------------|-------------------------------|
| Rated current at 40°C | 4 A |
| Rated voltage | 24 V |
| Number of positions | 3 |
| Contact resistance | ≤ 5 mΩ |
| Insulation resistance | ≥ 100 MΩ |
| Standards/regulations | Valve connector EN 175301-803 |
| Status display | 1 LED |
| Protective circuit/component | Z diode |
| Surge voltage category | III |
| Pollution degree | 3 |
| Torque | 0.6 Nm (Valve connector) |

Sensor/Actuator cable - SAC-3P- 1,5-PUR/A-1L-Z - 1434989

Technical data

Material

| | |
|---|-------------------|
| Inflammability class according to UL 94 | V0 |
| Valve plug contact material | CuSn |
| Valve plug contact surface material | Sn |
| Valve plug contact insert material | PA 66 |
| Material housing valve plug | TPU |
| Sealing material | TPU (Seal molded) |

Cable

| | |
|---|--|
| Cable type | PUR halogen-free black |
| Cable type (abbreviation) | PUR |
| Cable abbreviation | Li9Y11Y-HF |
| UL AWM style | 20549 |
| Conductor cross section | 3x 0.5 mm ² |
| AWG signal line | 20 |
| Conductor structure signal line | 28x 0.15 mm |
| Core diameter including insulation | 1.5 mm ±0.05 mm (signal line) |
| Wire colors | black 1, black 2, green/yellow |
| Overall twist | 3 wires, twisted |
| External sheath, color | Black-gray RAL 7021 |
| External cable diameter D | 4.5 mm ± 0.2 mm |
| Smallest bending radius, fixed installation | 22.5 mm |
| Number of bending cycles | 15000000 |
| Bending radius | 50 mm |
| Traversing path | 0.9 m |
| Traversing rate | 5 m/s |
| Acceleration | 30 m/s ² |
| Outer sheath, material | PUR |
| Material conductor insulation | PP |
| Conductor material | Bare Cu litz wires |
| Insulation resistance | min. 20 MΩ*km |
| Conductor resistance | 39 Ω/km (at 20 °C) |
| Nominal voltage, cable | ≤ 300 V |
| Test voltage, cable | ≥ 1200 V |
| Flame resistance | According to DIN VDE 0482 |
| Flame resistance | According to DIN EN 50265-2-1 |
| Halogen-free | in accordance with DIN VDE 0472 part 815 |
| Other resistance | Largely oil-resistant |
| Other resistance | partly UV-resistant in accordance with DIN EN ISO 4892-2-A |
| Ambient temperature (operation) | -40 °C ... 80 °C (cable, fixed installation) |
| Ambient temperature (operation) | -20 °C ... 80 °C (cable, flexible installation) |

Sensor/Actuator cable - SAC-3P- 1,5-PUR/A-1L-Z - 1434989

classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 4.0 | 27060306 |
| eCl@ss 4.1 | 27060306 |
| eCl@ss 5.0 | 27061801 |
| eCl@ss 5.1 | 27061801 |
| eCl@ss 6.0 | 27061801 |
| eCl@ss 7.0 | 27061801 |
| eCl@ss 8.0 | 27061801 |

ETIM

| | |
|----------|----------|
| ETIM 3.0 | EC001855 |
| ETIM 4.0 | EC001855 |
| ETIM 5.0 | EC001855 |

UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 31251501 |
| UNSPSC 7.0901 | 31251501 |
| UNSPSC 11 | 31251501 |
| UNSPSC 12.01 | 31251501 |
| UNSPSC 13.2 | 31251501 |

approvals

GOST /

Approval details



accessories

Mounting material

SAC-V-SCREW-M3-29 KNURL - 1403779



Torque tool

Sensor/Actuator cable - SAC-3P- 1,5-PUR/A-1L-Z - 1434989

accessories

TSD-M 1,2NM - 1212224



Screwdriver tools

SF-BIT-PH 1-70 - 1212582



Conductor marking

PABA WH/15 - 1013151



PABA YE/15 - 1013698



PABA RD/15 - 1013944



Marker carrier cable

Sensor/Actuator cable - SAC-3P- 1,5-PUR/A-1L-Z - 1434989

accessories

PATG 2/15 - 1013038



PATG 3/15 - 1013041



PATG 4/15 - 1013054



Marker pen

B-STIFT - 1051993



Cutting tools

CUTFOX-S VDE - 1212207



Stripping tool

Sensor/Actuator cable - SAC-3P- 1,5-PUR/A-1L-Z - 1434989

accessories

WIREFOX SAC - 1212623



WIREFOX 10 - 1212150




accessories

WIREFOX SAC-1 - 1212757

Drawings


Sensor/Actuator cable - SAC-3P- 1,5-PUR/A-1L-Z - 1434989

Dimensioned drawing

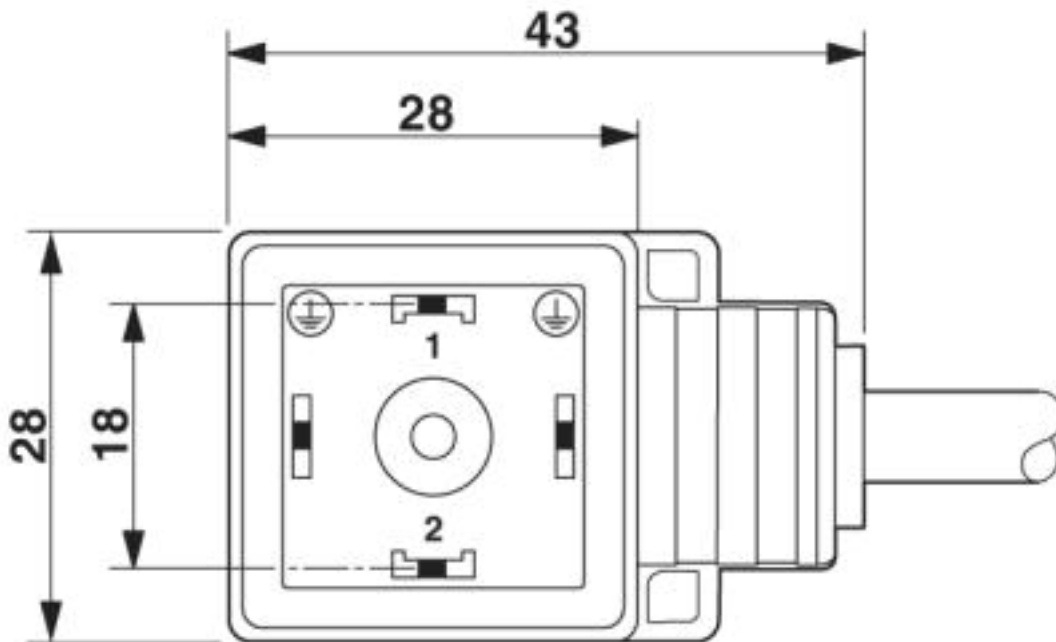

Valve connector, type A


Dimensioned drawing

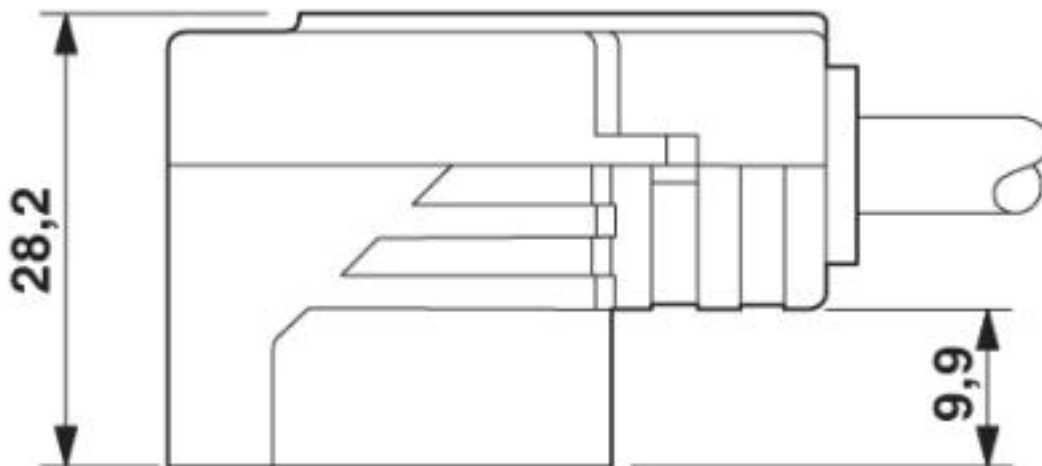

Valve connector, type A, side view

Sensor/Actuator cable - SAC-3P- 1,5-PUR/A-1L-Z - 1434989


Circuit diagram

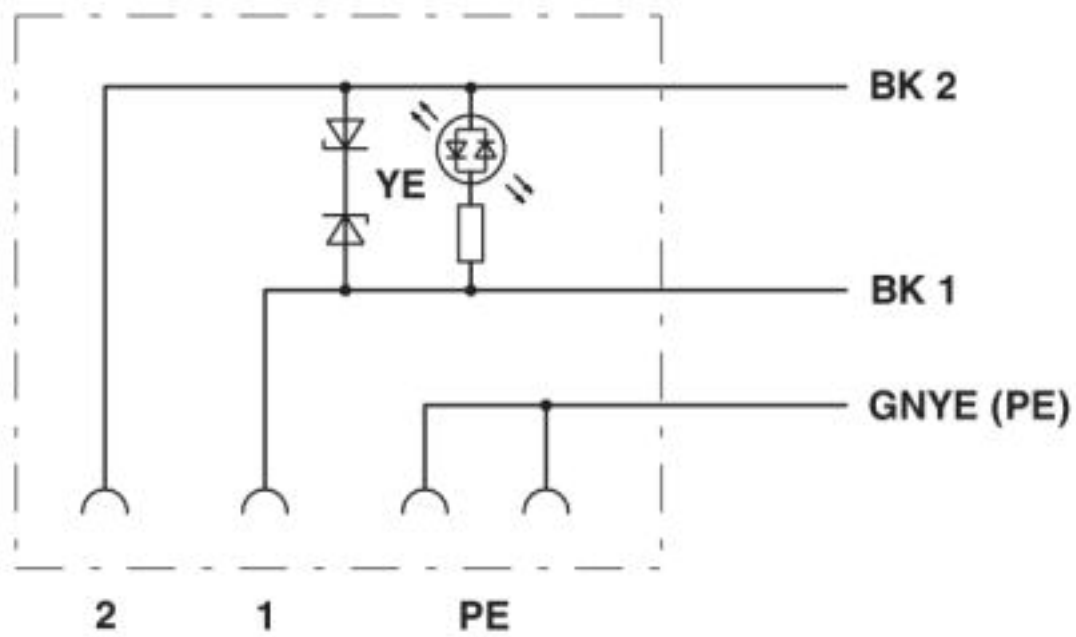

Contact assignment of the valve plug

Sensor/Actuator cable - SAC-3P- 1,5-PUR/A-1L-Z - 1434989


Schematic diagram

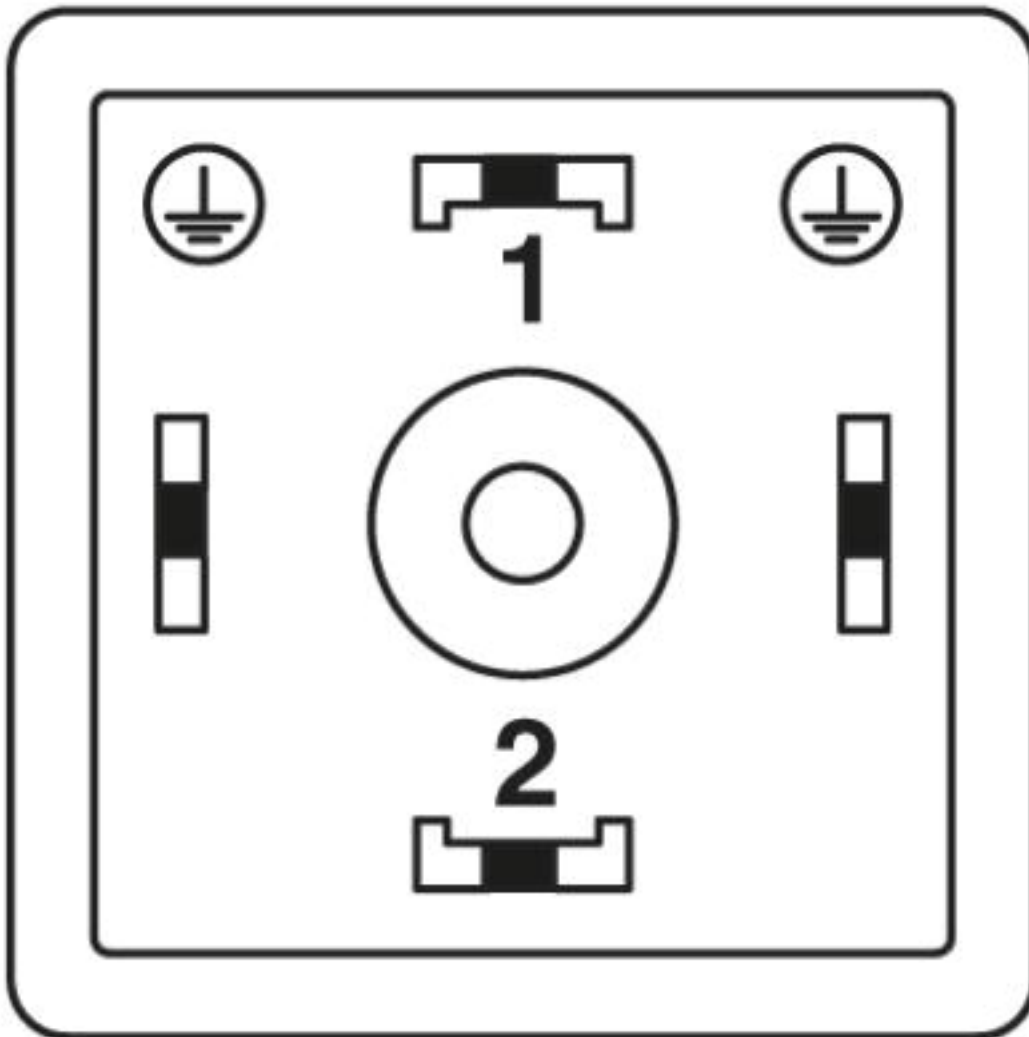

Valve connector pin assignment, type A

Sensor/Actuator cable - SAC-3P- 1,5-PUR/A-1L-Z - 1434989

Cable cross section

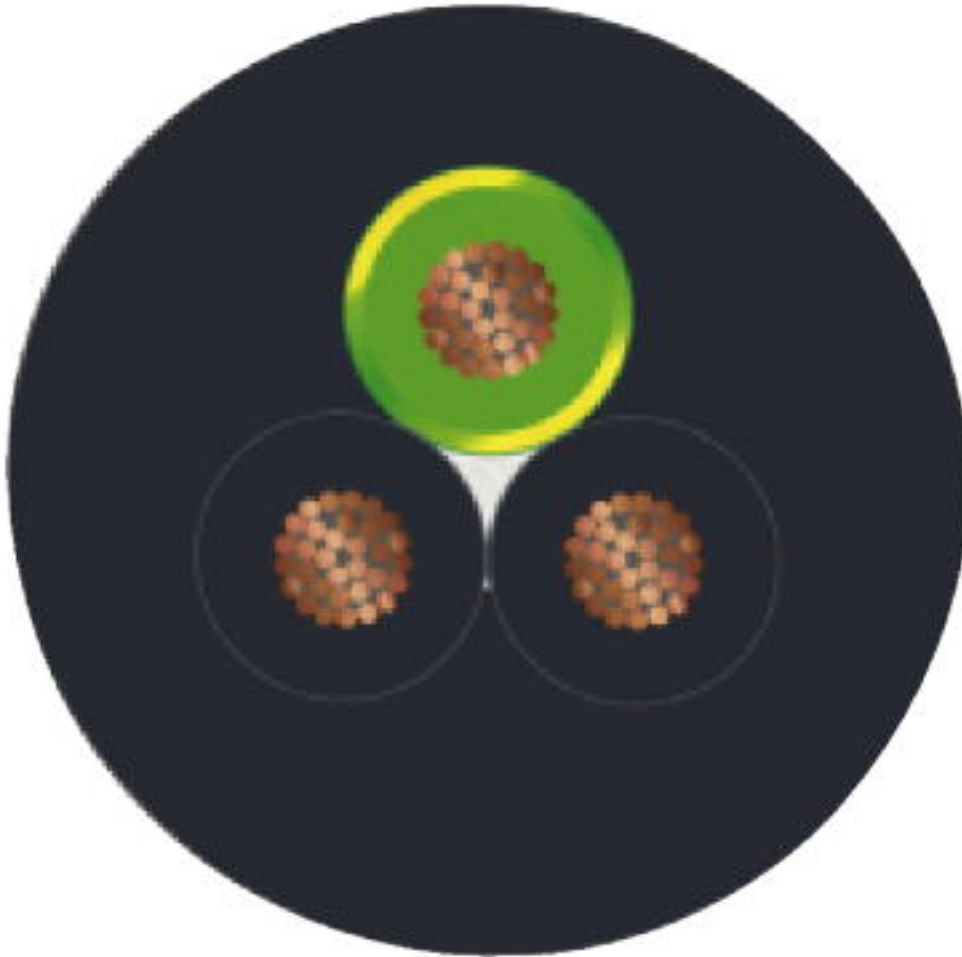

PUR halogen-free black [PUR]

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>