

Filler plugs - HC-M-BS-M16 - 1646227

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Filler plug, metal, size: M16

Key commercial data

package_quantity	10
GTIN	4017918927981

Technical data

Ambient conditions

Degree of protection	IP68
Degree of protection	IP68
Ambient temperature (operation)	-20 °C ... 80 °C

General

Material	Nickel-plated brass
Seal material	NBR
Material, O-ring	NBR
Thread type on connection side	M16
Color	silver

classifications

eCl@ss

eCl@ss 4.0	27141209
eCl@ss 4.1	27141209
eCl@ss 5.0	27149109
eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 7.0	27149109
eCl@ss 8.0	27149109

ETIM

ETIM 2.0	EC000441
ETIM 3.0	EC000441
ETIM 4.0	EC000032

Filler plugs - HC-M-BS-M16 - 1646227

classifications

ETIM


ETIM 5.0	EC000032
-----------------	----------

UNSPSC

UNSPSC 6.01	30211808
UNSPSC 7.0901	39121408
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	39121408

Drawings

Dimensioned drawing

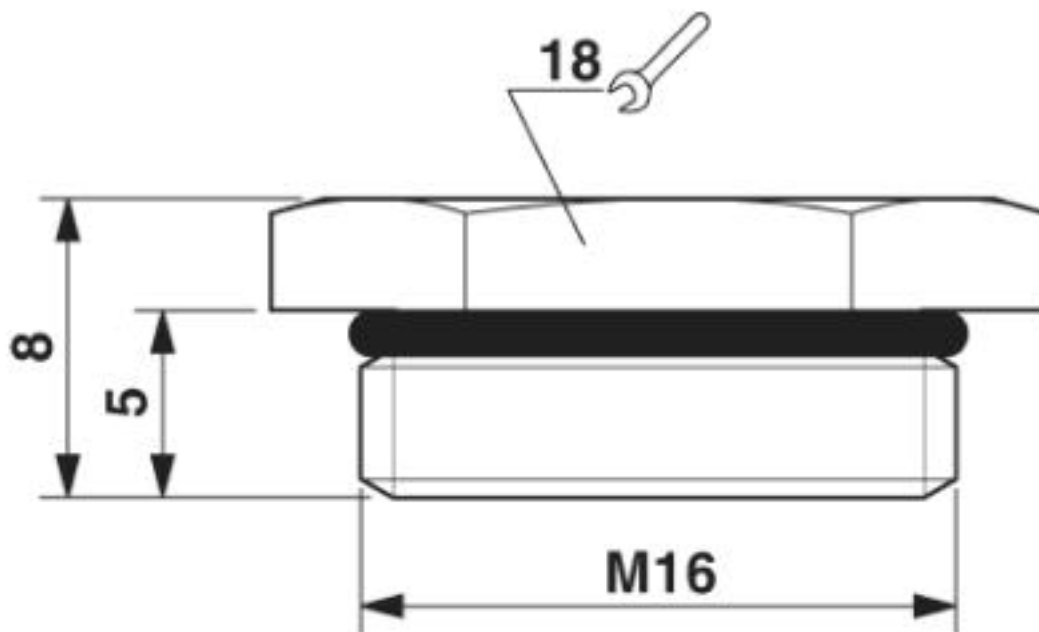

M16 filler plugs