

## Cable duct - CD-HF 40X40 - 3240348

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Cable duct, light gray, halogen-free, consisting of upper part and mounting base, width: 40 mm, height: 40 mm, length: 2000 mm

The illustration shows the version in gray

### Product Features

- ✓ Predetermined breaking point enables tool-free, burr-free removal of bars
- ✓ Fast and seamless creation of T and cross connections by means of an additional predetermined breaking point in the cable duct base
- ✓ The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- ✓ Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- ✓ Cover is securely held in place for both horizontal and vertical mounting

### Key commercial data

|                  |               |
|------------------|---------------|
| package_quantity | 25            |
| GTIN             | 4046356508339 |

### Technical data

#### Dimensions

|            |         |
|------------|---------|
| Length (b) | 2000 mm |
| Height     | 40 mm   |
| Width (a)  | 40 mm   |

#### Ambient conditions

|                                 |                  |
|---------------------------------|------------------|
| Ambient temperature (operation) | -25 °C ... 90 °C |
|---------------------------------|------------------|

#### General

|                                         |              |
|-----------------------------------------|--------------|
| Color                                   | light gray   |
| Components                              | Halogen-free |
| Inflammability class according to UL 94 | V0           |
| Material                                | PC/ABS       |

### classifications

#### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 4.0 | 27140602 |
| eCl@ss 4.1 | 27140602 |

## Cable duct - CD-HF 40X40 - 3240348

### classifications

#### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 5.0 | 27140602 |
| eCl@ss 5.1 | 27140602 |
| eCl@ss 6.0 | 27400703 |
| eCl@ss 7.0 | 27400703 |
| eCl@ss 8.0 | 27400703 |

#### ETIM

|          |          |
|----------|----------|
| ETIM 2.0 | EC000012 |
| ETIM 3.0 | EC000012 |
| ETIM 4.0 | EC000012 |
| ETIM 5.0 | EC000012 |

 
 
#### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 30211812 |
| UNSPSC 7.0901 | 39121411 |
| UNSPSC 11     | 39121411 |
| UNSPSC 12.01  | 39121708 |
| UNSPSC 13.2   | 39121411 |

### approvals

CSA / UL Recognized / VDE Zeichengenehmigung /

#### Approval details



### accessories

#### Cover

## Cable duct - CD-HF 40X40 - 3240348

### accessories

CD-HF COVER 40 - 3240371



---

### Slotted cable trunking system

CD WR - 3240284



---

### Filler plug

RVT-PA 4 - 3240498



RVT-PA 6 - 3240499



---

### Riveting tools

UNIFOX-RVT P 4 - 1212478



## Cable duct - CD-HF 40X40 - 3240348


accessories

UNIFOX-RVT P 6 - 1212509



### Drawings

Dimensioned drawing

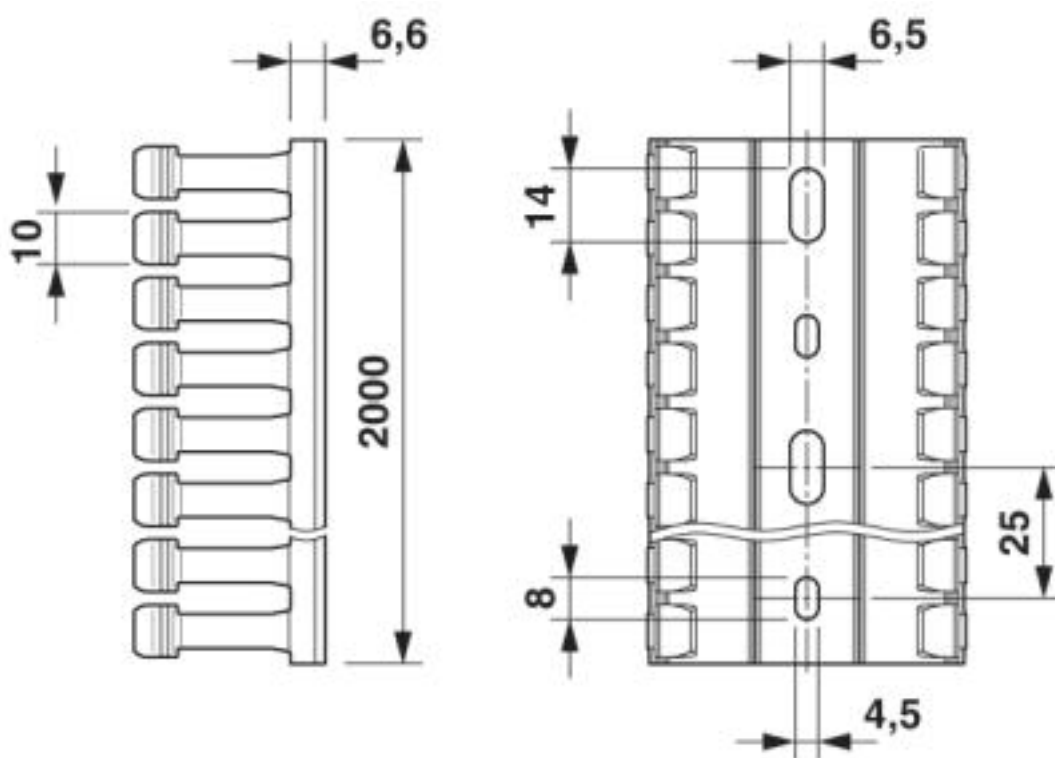

Base perforation according to DIN EN 50085

© Phoenix Contact 2013 - all rights reserved  
<http://www.phoenixcontact.com>