


# Technical datasheet: KPMB-G38012-K8477

## Specifications:

Operating Temperature Range	-20°C to +60°C
Storage Temperature Range	-30°C to +70°C
Rated Voltage	12 VAC/ 50Hz
Operation Voltage	10.5 VAC to 13.5 VAC
Min. Sound Pressure Level	75dB/ 12VAC/ 20cm
Max. Rated Current	250mA
Coil Resistance	54.5 ± 10% Ω
Housing Material	ABS

## Dimensions:

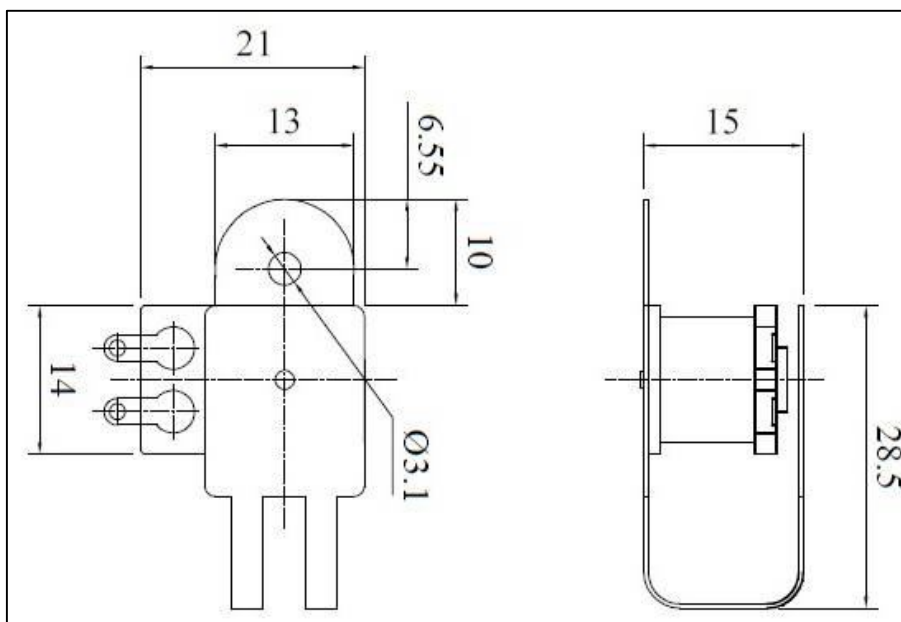

## Response Curve:

