
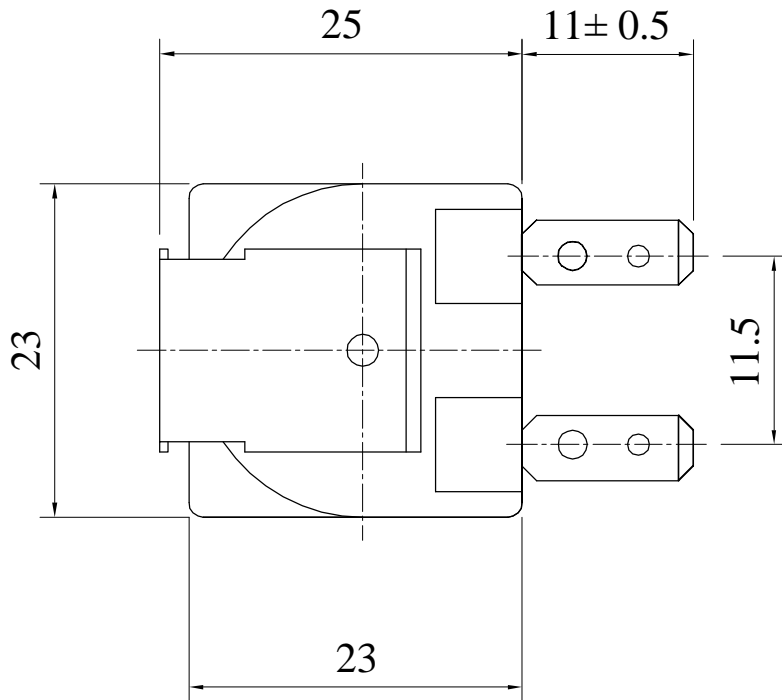


受 控

SPECIFICATION

- 1. Rated Voltage24VAC/50~60Hz
- 2. Operating Voltage20~28VAC
- 3. Max. Rated Current180mA at 24VAC
- 4. Coil Resistance100 Ω ±10%
- 5. Min. Sound Pressure Level.....75dB at 24VAC/20cm
- 6. Case Material/Colornull
- 7. Operating Temperature-25~+75°C
- 8. Store Temperature-30~+80°C
- 9. Weight26g

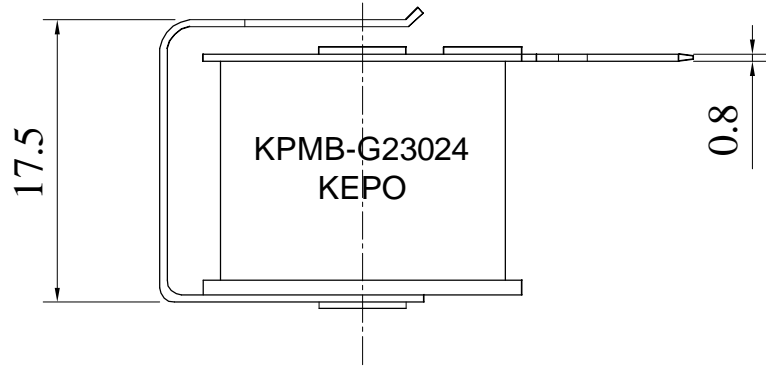

				Compliance with ROHS	
				KEPO NINGBO KEPO ELECTRONIC CO.,LTD http://www.chinaacoustic.com	
				Mechanical Buzzer soundford	
				KPMB-G23024-K7539	
No.	DESCRIPTION	MENDER	DATE	UNIT	DWG NO.
TOLERANCES UNLESS NOTED OTHERWISE: .X * .XX * .XXX * 90° FORMED ±.2° ANGLES ±.1°		APPROVALS			
		DRAWN	DATE		
		胡浩波	10.12.20		
		CHECKED			
		APPROVED			
FIRST ANGLE PROJECTION				mm	OEM7539R
		SCALE		SHEET	VER 1.0