

## Cable lug - C-PCI 2,5/2 - 3240066

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Pin cable lug, blue, 1.5 - 2.5 mm<sup>2</sup>, L1=12 mm

### Product Features

- Hard-soldered crimping zone for maximum pull-out forces
- Electrolytic tin plating
- Halogen-free
- 'EASY ENTRY' for easy and reliable conductor entry

### Key commercial data

package_quantity	100
GTIN	4046356452847

### Technical data

#### Dimensions

Length (b)	23 mm
Length contact range	12 mm
Length of insulation sleeve (c)	11 mm
Inner dimension of the insulating collar (d)	4.5 mm
Inner diameter (f)	2 mm
Material thickness (g)	0.8 mm

#### Ambient conditions

Ambient temperature (operation)	-20 °C ... 105 °C
---------------------------------	-------------------

#### General

Color	blue
Stripping length	8 mm
Components	Halogen-free
Inflammability class according to UL 94	V2
Material	Copper

### classifications

#### eCl@ss

eCl@ss 4.0	27060701
------------	----------

## Cable lug - C-PCI 2,5/2 - 3240066

### classifications

#### eCl@ss

eCl@ss 4.1	27060701
eCl@ss 5.0	27400201
eCl@ss 5.1	27400201
eCl@ss 6.0	27400201
eCl@ss 7.0	27400201
eCl@ss 8.0	27400201

#### ETIM

ETIM 2.0	EC000005
ETIM 3.0	EC000005
ETIM 4.0	EC001052
ETIM 5.0	EC001052


#### UNSPSC

UNSPSC 6.01	27113201
UNSPSC 7.0901	27121703
UNSPSC 11	27121703
UNSPSC 12.01	27121703
UNSPSC 13.2	27121703

### Drawings

# Cable lug - C-PCI 2,5/2 - 3240066

Dimensioned drawing

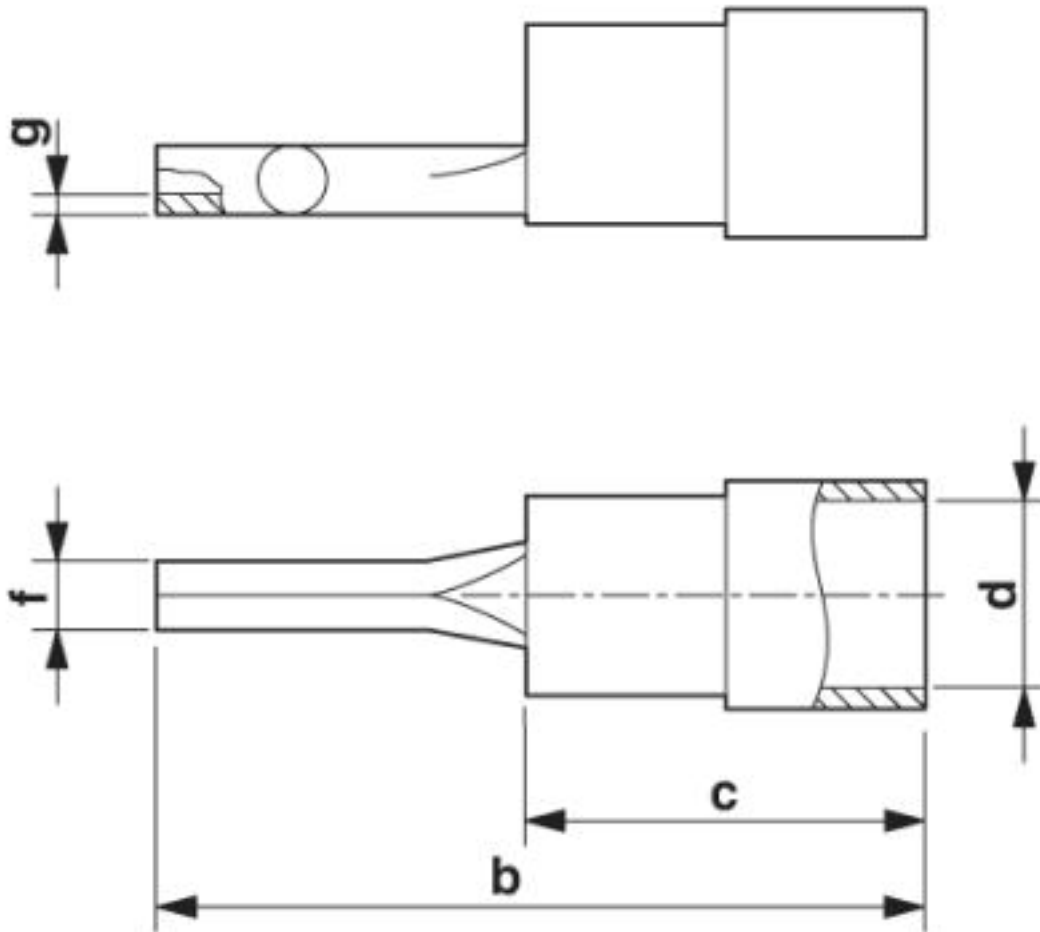

© Phoenix Contact 2013 - all rights reserved  
<http://www.phoenixcontact.com>