


Lamp : 12V 60mA
 Life 5000 hours
 Insulation Resistance : DC 500v more than 100M Ohm
 Voltage Breakdown : AC 1000v / 1 minute
 Material of body : Polycarbonate
 Material of insulation tube : UL AWG18

SEDECO	B-414A INDICATOR LIGHT	B/N 722723 (12V CLEAR)
---------------	------------------------	------------------------

DRAWINGS WITH DIMENSIONS (Unit: mm)

LAMP : 12V 60mA
 Life = 5,000 Hours
 INSULATION RESISTANCE : DC 5000V More Than 100MΩ
 VOLTAGE BREAKDOWN : AC 1000V / 1 Minute

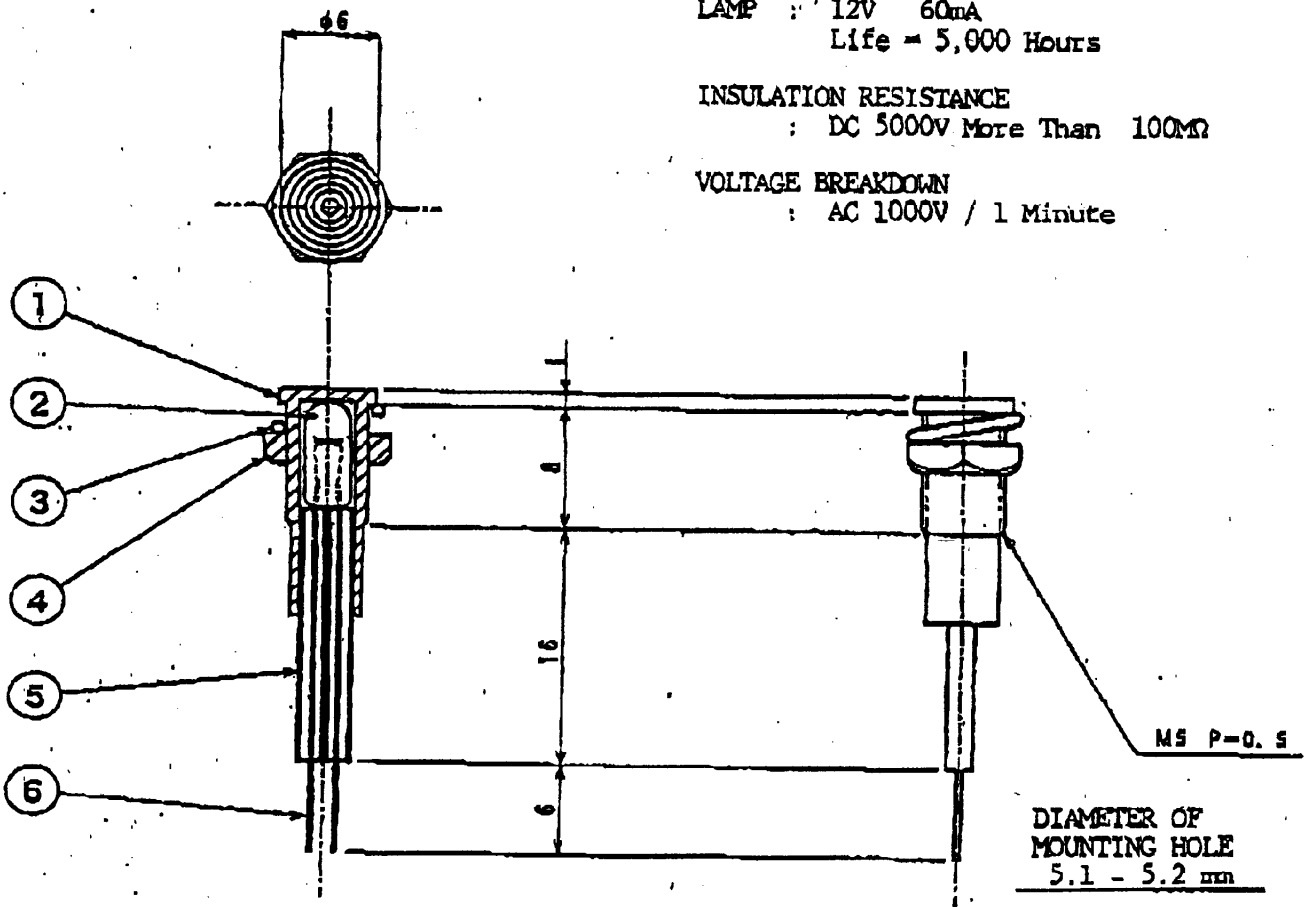

PARTS NAME & MATERIALS

- | | | |
|--------------------|---|------------------------------|
| 1) BODY | : | POLYCARBONATE (CLEAR) |
| 2) LAMP | : | 12V 60mA |
| 3) SPRING WASHER | : | BRASS (B52M2) W/NICKEL PLATE |
| 4) HEXAGONAL NUT | : | STEEL (SWP) W/NICKEL PLATE |
| 5) INSULATION TUBE | : | UL AWG 18 (BLACK) |
| 6) LEADS TERMINAL | : | DIMET WIRE |