
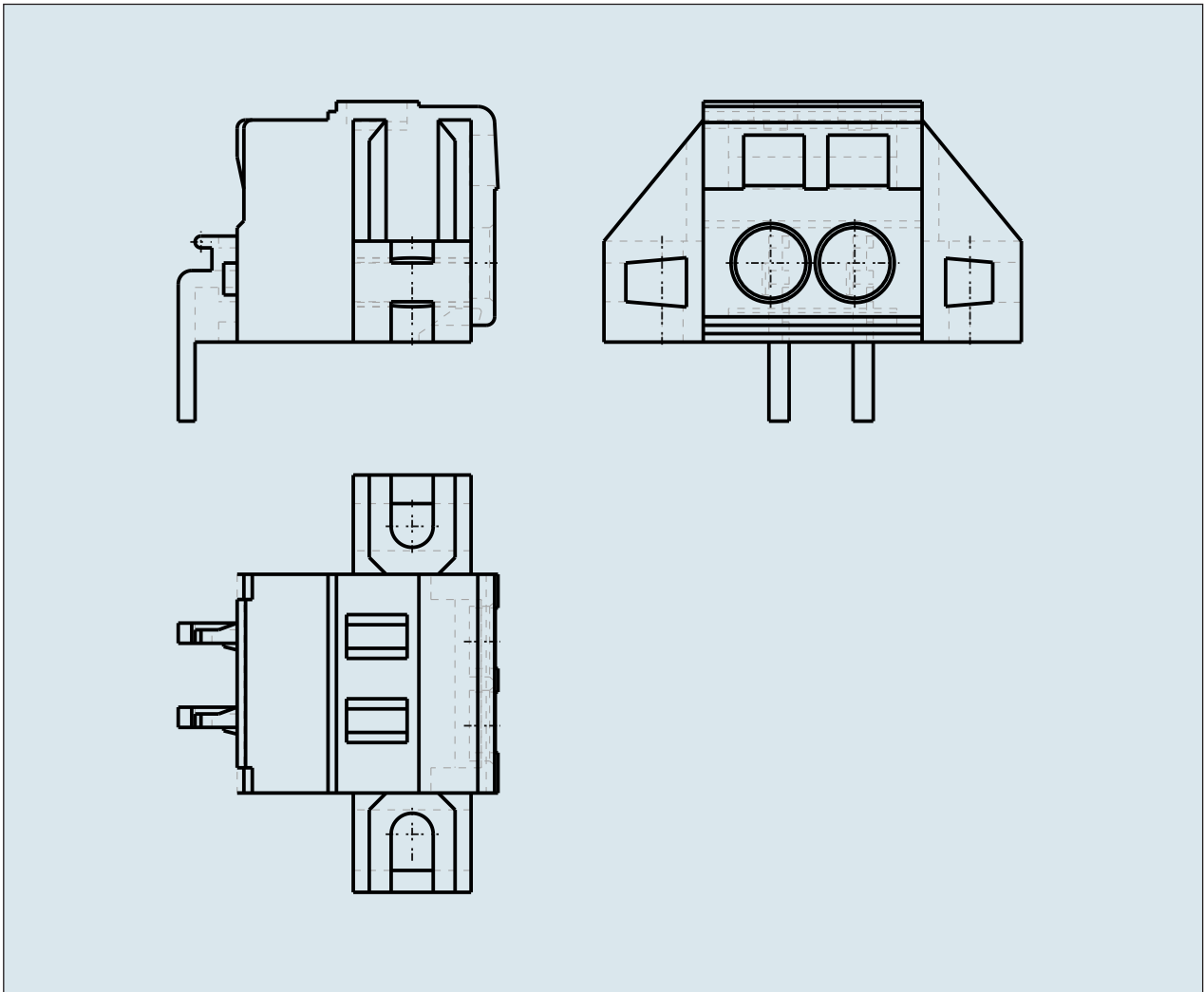


**HEADER WITH FIXING FLANGE PIN
SPACING 5 MM / 0.197 IN 100%
PROTECTED AGAINST MISMATING
WITH PRECEDING EARTH CONTACT**

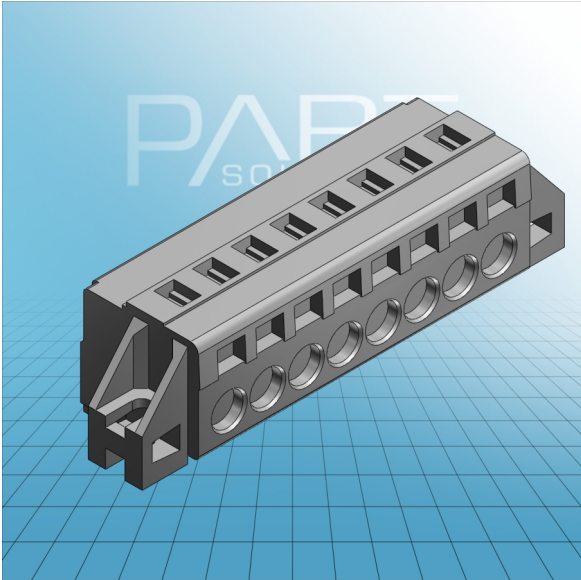

**HEADER WITH FIXING FLANGE PIN
SPACING 5 MM / 0.197 IN 100%
PROTECTED AGAINST MISMATING
WITH PRECEDING EARTH CONTACT
231-602/023-000 TO 231-612/023-000**

ITEM-NO. (ITEM-NO.)	231-608/023-000
Cross section1 (Cross section / mm²)	0.08 - 2.5
Cross section2 (Cross section / AWG)	28 - 14
Strip length (Strip length / mm)	8 - 9
Measured voltage (Measured voltage / V)	320
Measured shock voltage (Measured shock voltage / kV)	4
Pollution degree (Pollution degree)	2
Current intensity (Current intensity / A)	16
RM (PIN SPACING / mm)	5
P (NO. OF POLES)	8
Height (Height / mm)	14.3
Width (Width / mm)	55.2
Depth (Depth / mm)	19.1
No. of connection Points (No. of connection Points)	8
No. of potentials (No. of potentials)	8
COLOR (COLOR)	grau
WEIGHT (WEIGHT / g)	11.4
Comment (Comment)	L = (No. of poles x Pin Spacing) + 3 mm L1 = L + 5,8 mm L2 = L1 + 6,4 mm
Dimensions (Dimensions)	1,8 + 0,1 mm