



**FEMALE PLUG WITH STRAIGHT
LONG CONTACT PINS PIN SPACING
7,5 mm / 0.295 in**
232-732/005-000 TO 232-742/005-000

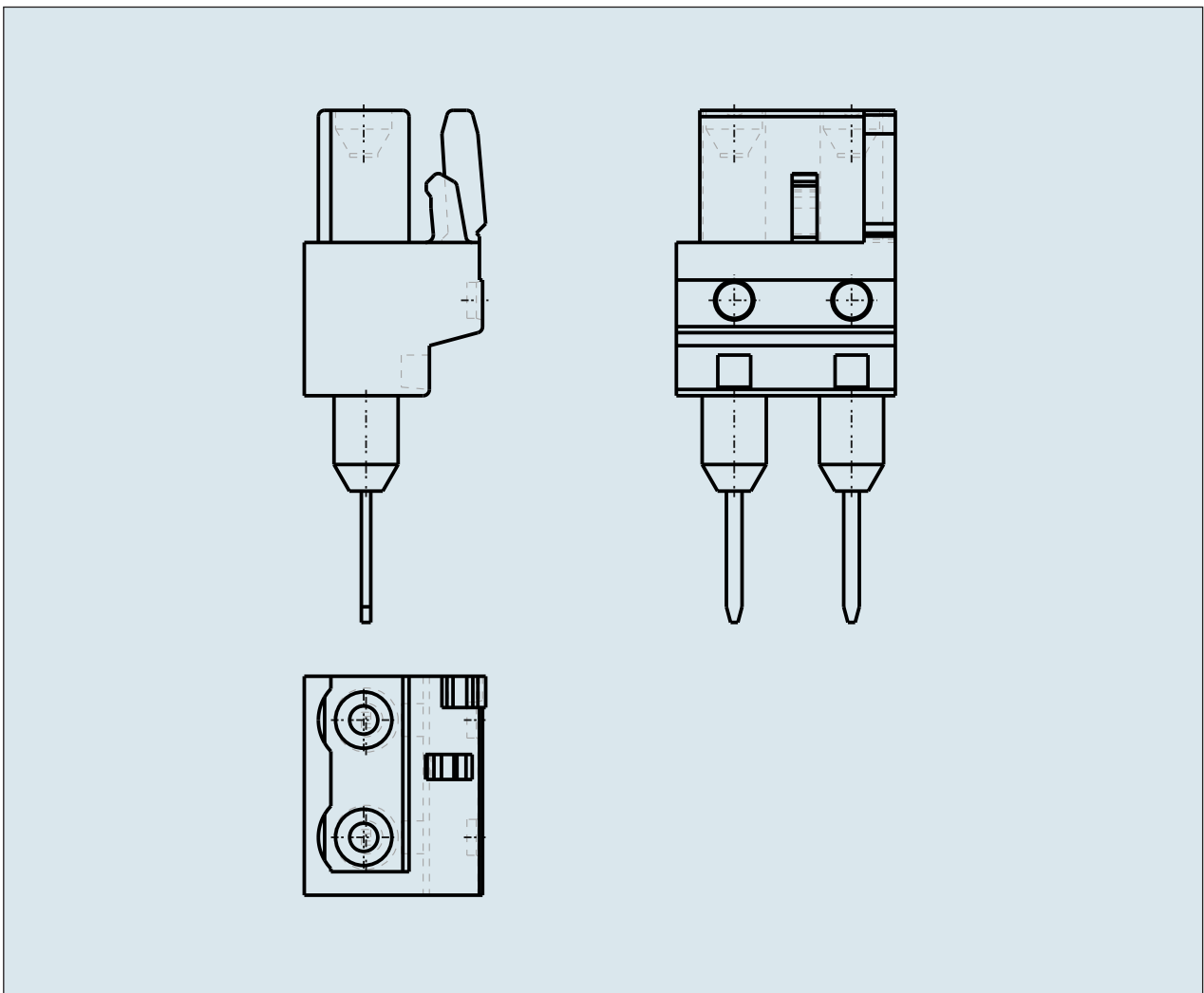

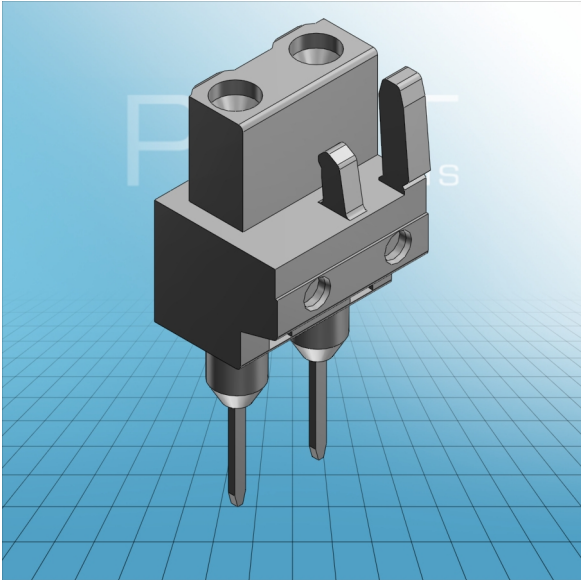

**FEMALE PLUG WITH STRAIGHT
LONG CONTACT PINS PIN SPACING
7,5 mm / 0.295 in
232-732/005-000 TO 232-742/005-000**

ITEM-NO. (ITEM-NO.)	232-732/005-000
Measured voltage (Measured voltage / V)	400
Measured shock voltage (Measured shock voltage / kV)	6
Pollution degree (Pollution degree)	3
Current intensity (Current intensity / A)	12
RM (PIN SPACING / mm)	7.5
P (NO. OF POLES)	2
Height (Height / mm)	18.25
Width (Width / mm)	14
Depth (Depth / mm)	11.6
COLOR (COLOR)	grau
WEIGHT (WEIGHT / g)	2.34
Comment (Comment)	L = (No. of poles x Pin Spacing) + 1,5 mm