


Plugs

SLS 200

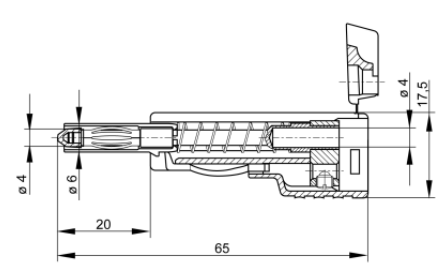

4 mm sliding sleeve system

Product	SLS 200
description	<p>Contact protected plug with screw connection for cables up to 2.5 mm², with onward connection capability (4 mm socket). Insulated by latching and sprung insulating sleeve, to be released by pressure on the lateral locking spring.</p> <p>plug with contact spring, 4mm diameter.</p> <p>*For this typ up to DC 150 V, CAT II according IEC/EN 61010-31 item 6.4., comment 4 allowed for devices with not yet protected sockets.</p>
operating instruction	BA412
article-no. / *colour	<p>9321531xx</p> <div style="display: flex; justify-content: space-around; align-items: center;"> <div style="text-align: center;">● 00 black</div> <div style="text-align: center;">● 01 red</div> <div style="text-align: center;">● 02 blue</div> <div style="text-align: center;">● 03 yellow</div> <div style="text-align: center;">● 04 green</div> </div> <div style="text-align: right; margin-top: 5px;">Ni</div>
drawing	
technical data	
connection	screw terminal
rated voltage ⁽¹⁾	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽³⁾
rated current ⁽¹⁾ (consider derating curve)	30 A
material plug	brass, nickel plated
housing material	PP
temperature range acc. To IEC61010 ⁽²⁾	-25 °C to +80 °C

standard	IEC 61010
----------	-----------

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges

⁽³⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 07.05.2019