
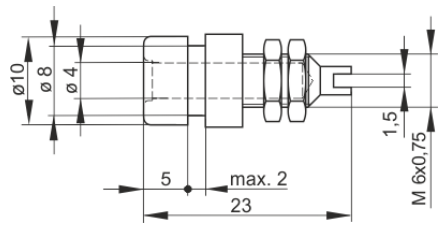


## Sockets

### BIL 20



Product	BIL 20
description	Socket with insulated head and ring for installation in equipment chassis and switchpanels with a wall thickness up to 2 mm. 4 mm diameter tin-plated zinc die-cast socket, with solder Connection and M6 thread.
operating instruction	BA403
article-no. / *colour	9301761xx 
drawing	
technical data	
connection	M6 thread, solder connection
rated voltage <sup>(1)</sup>	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O <sup>(3)</sup>
rated current <sup>(1)</sup> (consider derating curve)	32 A
housing material	PA
temperature range acc. To IEC61010 <sup>(2)</sup>	-25 °C to +85 °C
inflammability class acc. to UL 94 (only valid for basic material of housing)	V-2

<sup>(1)</sup> for normal environmental conditions 5°C to 40°C

<sup>(2)</sup> contact the manufacturer for applications at deviating temperature ranges

<sup>(3)</sup> without rated measurement category, for other circuits that are not directly connected to mains

stand: 16.08.2022