


## Sockets

### MSEB 2610 F 2,8 Au

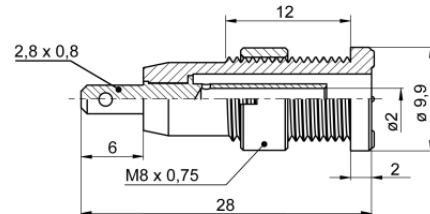

| Product                                                                     | MSEB 2610 F 2,8 Au                                                                                                                                                                                                                                                            |
|-----------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| description                                                                 | <p>Miniature safety built-in socket, 2mm diameter, gold-plated brass.</p> <p>Flat push-on Connection 2.8x0.8mm complying with DIN 46244.</p> <p>For installation into switch-panels and equipment Chassis till 8mm wall thickness.</p> <p>Installation hole: 8mm diameter</p> |
| operating instruction                                                       | BA254                                                                                                                                                                                                                                                                         |
| article-no. / *colour                                                       | <p>9754557xx</p> <div>  </div> <p><b>Au</b></p>                                                                                                                                            |
| drawing                                                                     |                                                                                                                                                                                                                                                                               |
|                                                                             |                                                                                                                                                                                           |
| technical data                                                              |                                                                                                                                                                                                                                                                               |
| connection                                                                  | flat connector 2.8 x 0.8 mm                                                                                                                                                                                                                                                   |
| rated voltage                                                               | AC/DC 1000 V                                                                                                                                                                                                                                                                  |
| measurement cat. acc. to IEC 61010                                          | CAT III                                                                                                                                                                                                                                                                       |
| rated current (consider derating curve)                                     | 10 A                                                                                                                                                                                                                                                                          |
| material socket                                                             | brass, gold plated                                                                                                                                                                                                                                                            |
| housing material                                                            | PA                                                                                                                                                                                                                                                                            |
| temperature range acc. To IEC61010 <sup>(1)</sup>                           | -25 °C to +70 °C                                                                                                                                                                                                                                                              |
| flammability class acc. to UL 94 (only valid for basic material of housing) | V-2                                                                                                                                                                                                                                                                           |

<sup>(1)</sup> contact the manufacturer for applications at deviating temperature ranges

stand: 21.06.2022

stand: 21.06.2022