


Sockets

SEB 2600 G M4

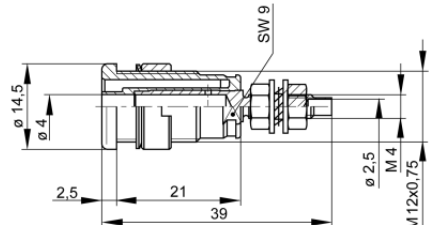

Product	SEB 2600 G M4
description	Safety built-in socket, 4 mm diameter, touch-protected, M 4 thread and solder connection, gold-plated brass. For installation into switch panels and equipment chassis with wall thicknesses up to 6 mm. Installation hole: 12.2 mm diameter, Tightening torque: 50 Ncm Accessory: assembly tool MW SEB
operating instruction	BA451
article-no. / *colour	9723541xx 00 black 01 red 02 blue 03 yellow 04 green 05 brown 06 gray 07 white 09 violet 88 yellow green Au
drawing	
	
technical data	
connection	M4 thread, solder connection
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	32 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-40 °C to +80 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

4 mm safety system

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 21.06.2022

stand: 21.06.2022