


Sockets

MSEB 2600 G M3 Au

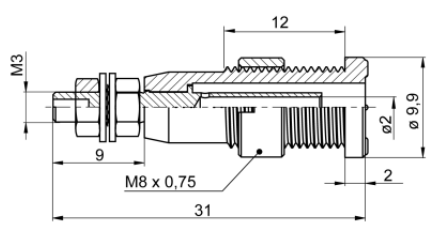

Product	MSEB 2600 G M3 Au
description	Miniature - safety built-in socket, 2mm diameter, touch protected, M3 threaded connection and soldering hole, gold-plated brass. For installation into switch- panels and equipment chassis with a wall thickness up to 8mm. Installation hole: 8mm diameter
operating instruction	BA254
article-no. / *colour	9754547xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green ● 05 brown ● 06 gray ● 07 white ● 09 violet Au
drawing	
	
technical data	
connection	M3 thread, solder connection
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	10 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

stand: 21.06.2022

stand: 21.06.2022